


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2000 kcmil
Wire Type	Stranded Copper; Class B: Compressed or Concentric
Wire Strip Length	3-5/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90 ° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	Brown
Panduit Die Index No. on Barrel	N/A
Alternate Industry Die Index No. () on Barrel	(34)

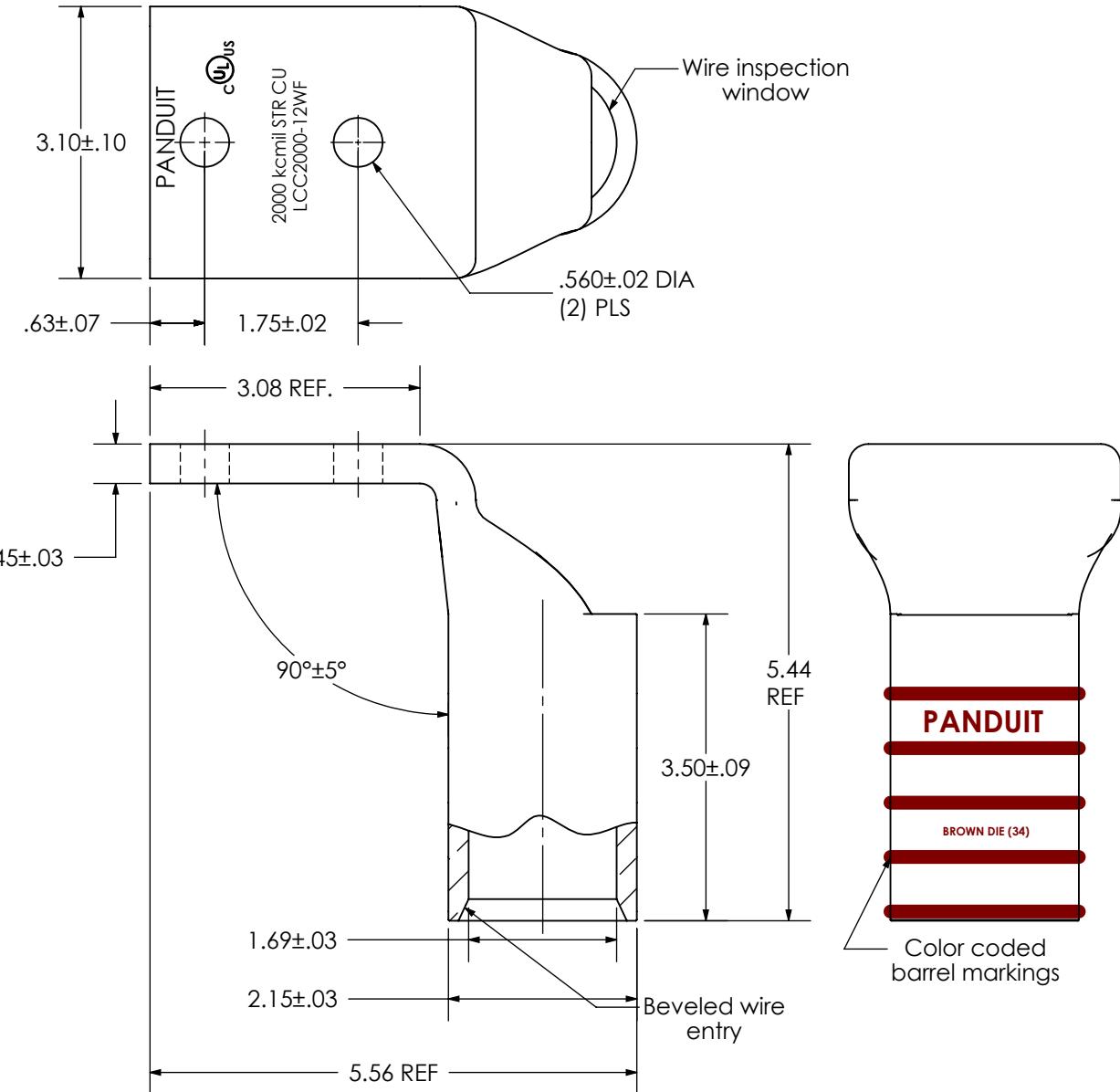

00	4/19	JHNU	TMR
DRAWING RELEASED			
REV	DATE	BY	CHK

DESCRIPTION

046154

ECN

SCALE
N/A

PANDUIT CORP. TINLEY PARK, ILLINOIS

LCC2000-12WF-1
Copper Lug - Two-Hole, Long Barrel with Window, 90° Angle Tongue

DRAWING NO / CAD FILE
LCC2000-12WF-CUST

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCC2000-12WF-1](#)