


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2000 kcmil
Wire Type	Stranded Copper; Class B: Compressed or Concentric
Wire Strip Length	3-5/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	Brown
Panduit Die Index No. on Barrel	N/A
Alternate Industry Die Index No. ( ) on Barrel	(34)

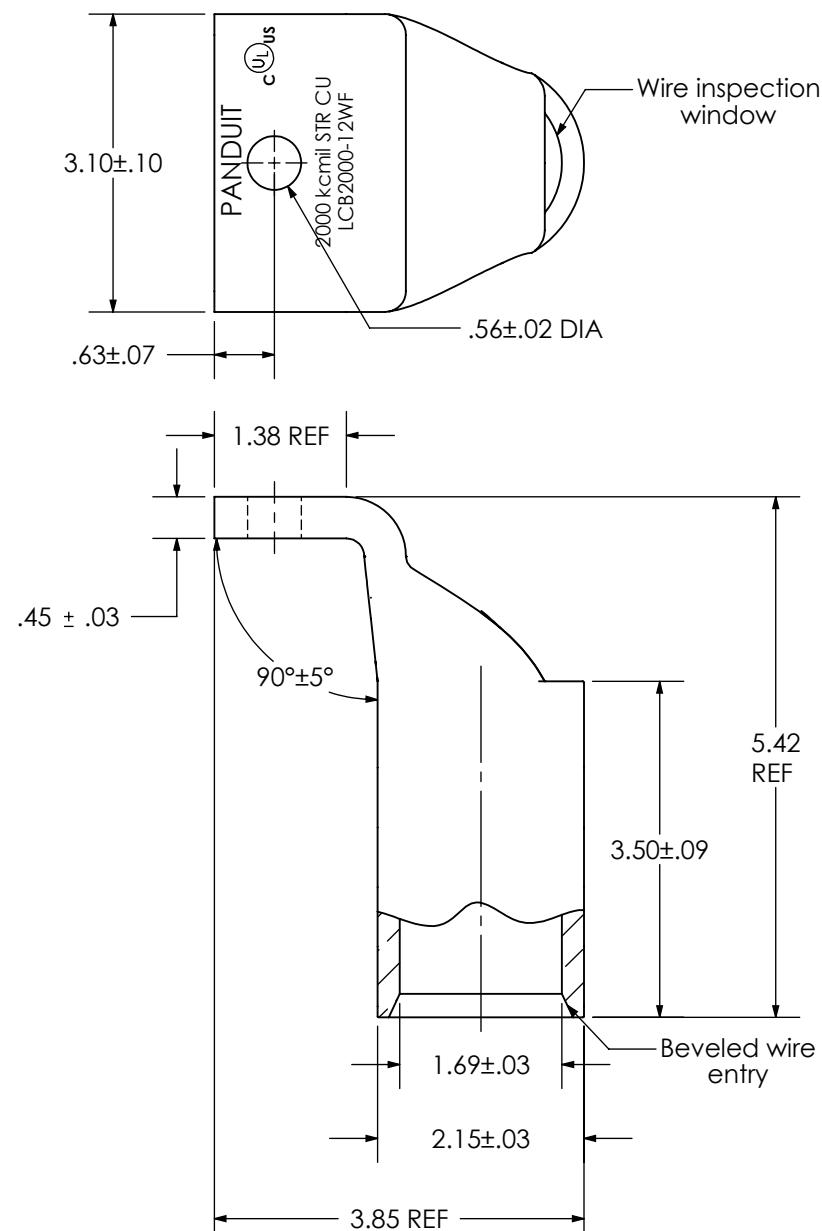

REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE	DRAWING NO / CAD FILE
01	4/19	JHNU	JHNU	REVISED WIRE STRIP LENGTH: 3-5/8 WAS 3-9/16 REVISED TONGUE LENGTH DIMENSION TO REF REVISED BARREL LENGTH TOLERANCE: ±.09 WAS ±.10	046154		<b>PANDUIT</b> CORP. TINLEY PARK, ILLINOIS
00	11/18	JHNU	JHNU	DRAWING RELEASED	NPI-PWRGRD-042761		LCB2000-12WF-1 Copper Lug - One-Hole, Long Barrel with Window, 90° Angle Tongue

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCB2000-12WF-1](#)