
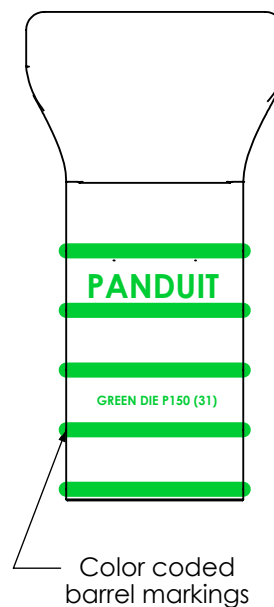


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	1500 kcmil
Wire Type	Stranded Copper; Class B; Compressed or Concentric
Wire Strip Length	3-3/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	Green
Panduit Die Index No. on Barrel	P150
Alternate Industry Die Index No. () on Barrel	(31)

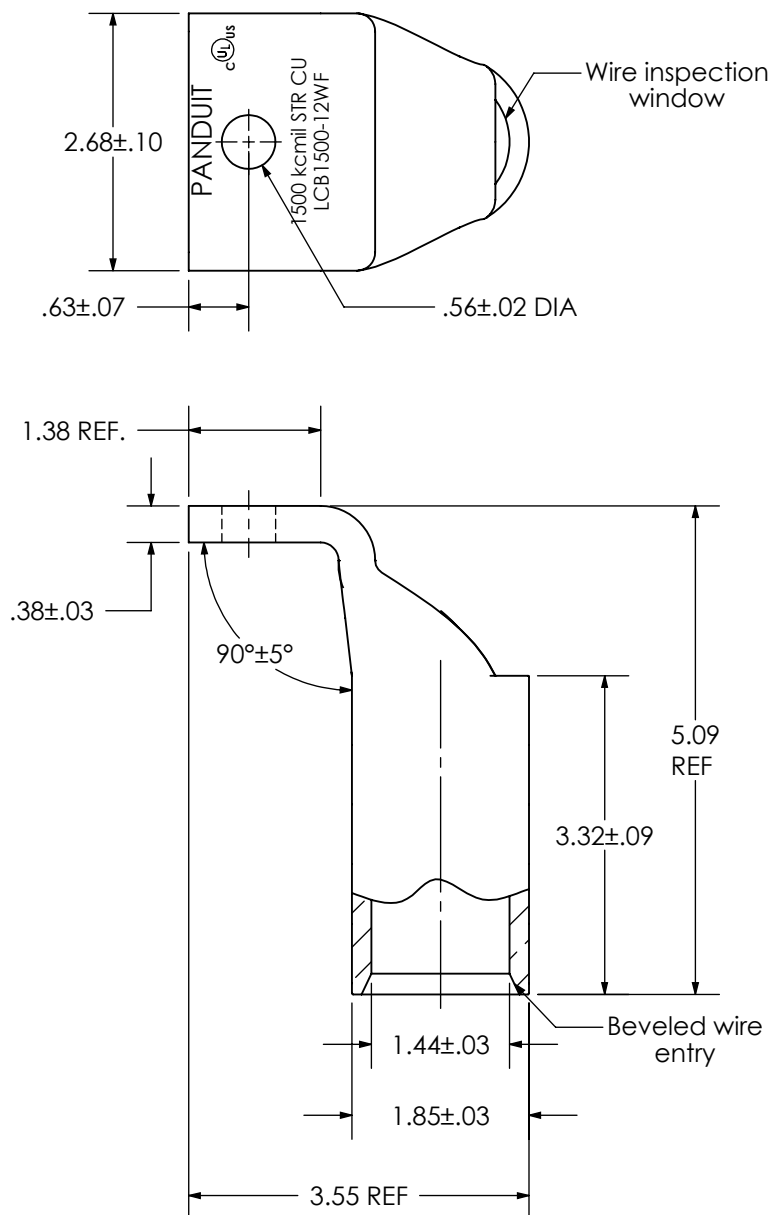

						 PANDUIT CORP. TINLEY PARK, ILLINOIS	
01	4/19	JHNU	JHNU	REVISED TOLERANCES, REVISED TONGUE LENGTH DIMENSION TO REFERENCE	046154	LCBI500-12WF-1 Copper Lug - One-Hole, Long Barrel with Window, 90° Angle Tongue	
00	11/18	JHNU	JHNU	DRAWING RELEASED	NPI-PWRGRD-042761		
REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCBI500-12WF-CUST

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCB1500-12WF-1](#)