


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Clear Coating
Wire Size	250 kcmil
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-9/16 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. UL Listed per UL467 for grounding and bonding and suitable for direct burial in earth or concrete.
UL Temperature Rating	90 °C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	RED
Panduit Die Index No. on Barrel	P71
Alternate Industry Die Index No. () on Barrel	(18)

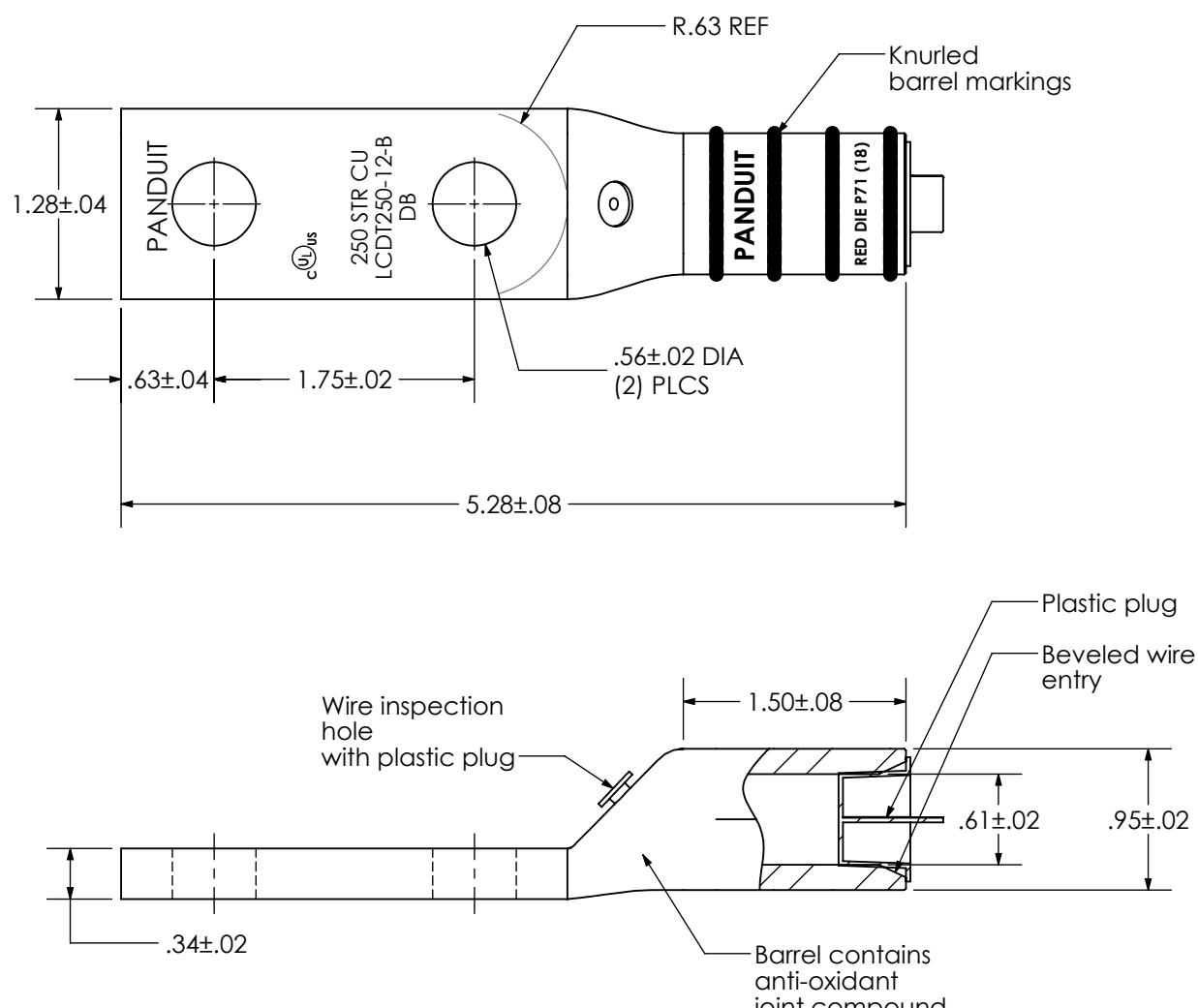

DB
RATED
MEETS
IEEE
837-2014



REV	DATE	BY	CHK	DESCRIPTION	NPI-PWRGRD-038781	RGB	RGB	PANDUIT	CORP. TINLEY PARK, ILLINOIS
02	8/18	JHNU	RGB	REVISED BARREL LENGTH: 1.50 WAS 1.18	LCDT250-12-B-CUST	RGB	RGB		LCDT250-12-B-X
01	5/17	JHNU	RGB	REVISED TOLERANCES ADDED IEEE LOGO					Copper Lug - Two-Hole, Standard Barrel, Direct Burial
00	3/16	JHNU	RGB	DRAWING RELEASED					
					ECN	-R	SUP	SCALE N/A	DRAWING NO / CAD FILE LCDT250-12-B-CUST

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[LCDT250-12-B-X](#)