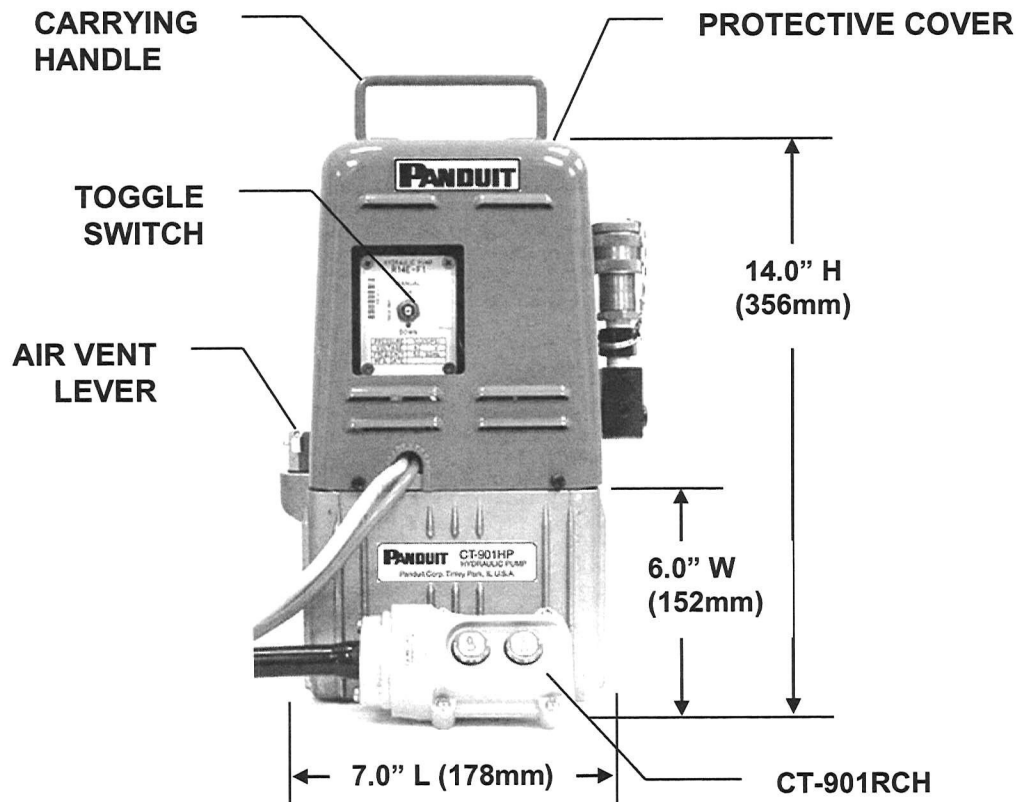


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.



NOTES, UNLESS OTHERWISE SPECIFIED:

FULLY AUTOMATIC PUMP SPECIFICATIONS

MOTOR:

 

Type: Commutator
RPM: 1200
Voltage: AC 120V
Frequency: 50/60 Hz
Current: 6.5A
Horsepower: 1/2

PUMP:

Low Pressure: 20kg/cm² (300 psi)
Delivery: 2.6 Liters/Min.
High Pressure: 600 Kg/cm² (10,000 psi)
Delivery: .32 Liters/Min.
Oil Tank Cap.: 2 Liters
Weight: 15 kg (33 lbs.)
Fluid Type: Shell Tellus S2V15 Hydraulic Oil
Housing Color: Orange

SEE SHEET 2 FOR FEATURES

F:\wrkgrp\rvusers\ENGR DOCS\CUST DWGS\TP24507A01 02 CT-901HP CD.doc

							CT-901HP HYDRAULIC PUMP CUSTOMER DRAWING					
							ITEM REVISION NAME:			<div>TP24507A01_02</div> <div>PANDUIT</div>		
							UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE:			MATERIAL:		
							(.x) ± --- (.xxx) ± --- (.xx) ± --- ANGLES ± ---			NONE		
							<div><div></div><div></div></div> THIRD ANGLE PROJECTION			DRAWING NUMBER: TP24507A01		
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	DRAWN BY: BLR	DATE: 8-03-07	CHK BJPU	SCALE NONE	SHT 1 OF 2	SIZE A
---	-----	----	----	----	UPD PHOTO, UPD BRANDING AND DWG.	----						
02	5-23-13	BLR			TEMPLATE; CHNG TO SHELL TELLUS S2V15 OIL	4609						
01	8-03-07	BLR	BJPU	ABJ	REDRAWN	4255						

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

NOTE: Used with separate crimping head, hydraulic pump and hose


 
- Crimps with CT-930CH, CT-940CH, and CT-980CH remote crimping heads:
 - CT-930CH – Accepts up to 750MCM Copper (600MCM Aluminum) lugs (400MCM Copper and Aluminum splices). Also specific C-Taps and H-Taps.
 - CT-940CH – Accepts up to 1500MCM Copper (1000MCM Aluminum) lugs and splices. Also specific C-Taps and H-Taps.
 - CT-980CH – Accepts 4 AWG to 750MCM Copper and Aluminum lugs and splices.
- CT-900HPH pre-filled hydraulic 10 foot hose

FEATURES:

- Manual Control
- Remote pump control
- Pressure adjustment 300 to 10,000 psi
- Visual fluid level
- External air vent and filler port
- Heavy gauge steel protective cover
- Two stage pumping action
- Automatic bypass when predetermined pressure is reached – pump shuts off automatically
- Built-in electrical solenoid switch to allow quick release of any cutter or crimper
- Small, compact, portable unit with carrying handle – standard 3/8" connection

SEE SHEET 1 FOR TOOL SPECIFICATIONS

F:\wrkgrp\rvusers\ENGR DOCS\CUST DWGS\TP24507A01_02 CT-901HP CD.doc

							CT-901HP HYDRAULIC PUMP							
							CUSTOMER DRAWING							
							ITEM REVISION NAME:							
							TP24507A01_02							
							UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE:				MATERIAL: NONE			
							(x) ± --- (.xxx) ± --- (xx) ± --- ANGLES ± ---							
											THIRD ANGLE PROJECTION			
02	5-22-13	----	----	----	SEE SHEET 1		----	DRAWN BY:		DATE:	CHK	SCALE	SHT 2 OF 2	SIZE A
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	BLR	8-03-07	BJPU	NONE				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[CT-901HP](#)