


Part Number: P4TI

Product Description: ROD HANGER FOR 1/4"-20 THREADED ROD - THREADED HOLE

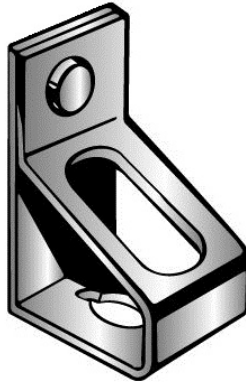

## Material Specifications

Type: High Carbon Steel, Spring Tempered

Finish: Zinc Phosphate and Oil

Color: Black

## Function Specifications

### Compatible Wires and Cables

AC/MC CABLE (OD):  
Drop Wire:  
Plain Rod (in):

### Threaded Rods and Bolts

Tapped Holes: 1/4-20  
Clearance Holes (in): 1/4 mounting hole  
Threaded Rod Size (in): 1/4

### Compatible Conduit

EMT Size (in):  
Rigid/IMC (in):

### Compatible Flanges and Studs

Flange Size (in):  
Metal Stud Size (ins):

### Static Load Rating

Vertical (lbs): 160  
Horizontal (lbs):

### Other

## Codes and Regulatory

Regulatory Certifications: -

Country of Origin: US

## Packaging

General Packaging: Cardboard Box  
Box Size: 7.5 X 5.5 X 4.5

Pieces per Package: 100  
Other Box Features: Fold out handle

## Document Information

Created By: DBLA  
Checked By: DJW  
Approved By: KLN

Customer Specification #: C11283  
Revision Level: 01  
ECN #: GAECN01482  
Date: 12/10/2013

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

P4TI