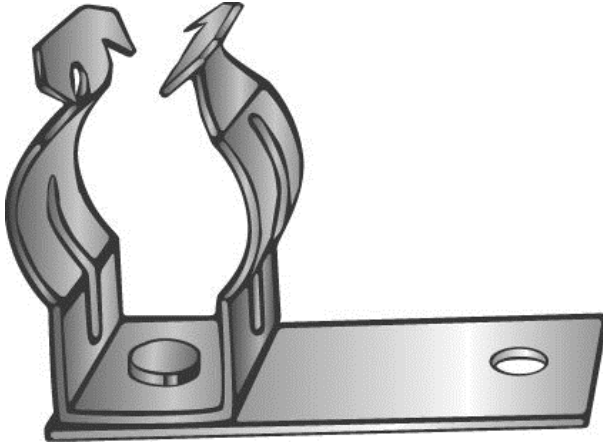


Part Number: PCNB12P

Product Description: NAIL/CONDUIT BRACKET WITH 3/4" PUSH FIT CONDUIT CLIP

**Material Specifications**

Type: Assembly

Finish: Assembly

Color: Various

**Function Specifications****Compatible Wires and Cables**

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):

**Threaded Rods and Bolts**

Tapped Holes:

Clearance Holes (in): 3/16

Threaded Rod Size (in):

**Compatible Conduit**

EMT Size (in): 3/4

Rigid/IMC (in): 1/2

**Compatible Flanges and Studs**

Flange Size (in):

Metal Stud Size (ins):

**Static Load Rating**

Vertical (lbs): Positioning Only

Horizontal (lbs): Positioning Only

**Other**

Attach to Wood, Metal, Concrete

**Codes and Regulatory**Regulatory  
Certifications: -

Country of Origin: US

**Packaging**

General Packaging: Cardboard Box

Box Size: 8.25 X 6.25 X 6

Pieces per Package: 100

Other Box Features:

**Document Information**

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11262

Revision Level: 01

ECN #: GAECN01482

Date: 12/10/2013

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[PCNB12P](#)