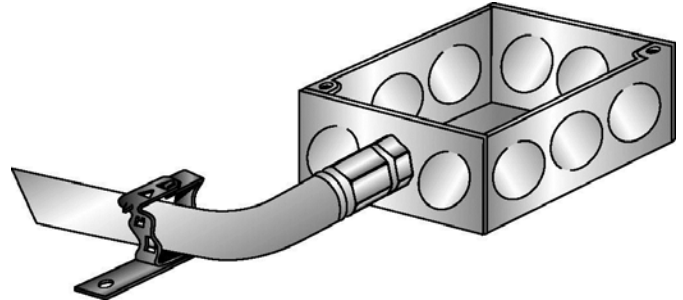
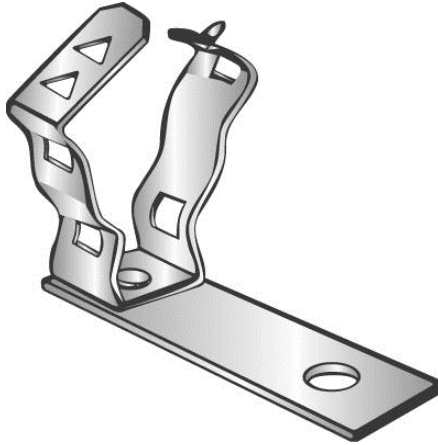


Part Number: PCNB812M

Product Description: NAIL/CONDUIT BRACKET WITH 1/2" - 3/4" PUSH FIT CONDUIT CLIP

**Material Specifications**

Type: Assembly

Finish: Assembly

Color: Various

Function Specifications**Compatible Wires and Cables**

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):

Threaded Rods and Bolts

Tapped Holes:

Clearance Holes (in): 3/16

Threaded Rod Size (in):

Compatible Conduit

EMT Size (in): 1/2 and 3/4

Rigid/IMC (in): 1/2 and 3/4

Compatible Flanges and Studs

Flange Size (in):

Metal Stud Size (ins):

Static Load Rating

Vertical (lbs): Positioning Only

Horizontal (lbs): Positioning Only

Other

Attach to Wood, Metal, Concrete

Codes and RegulatoryRegulatory
Certifications:

-

Country of Origin: US

Packaging

General Packaging: Cardboard Box

Box Size: 11 X 7.5 X 7.25

Pieces per Package: 100

Other Box Features:

Document Information

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11263

Revision Level: 01

ECN #: GAECN01482

Date: 12/10/2013

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[PCNB812M](#)