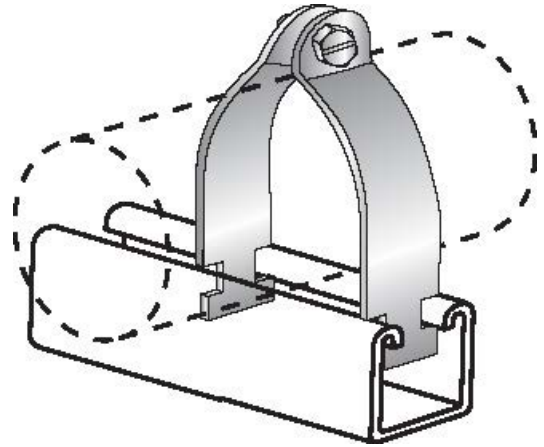
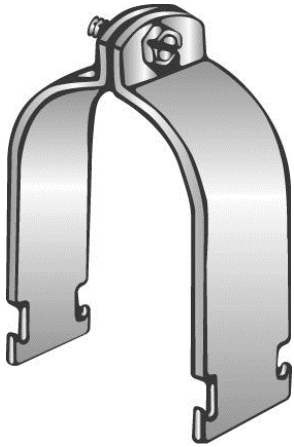


Part Number: PSK245I

Product Description: UNIVERSAL STRUT CLAMP FOR 1-1/2" CONDUIT

**Material Specifications**

Type: Hot Rolled, Pickled and Oiled Steel

Finish: Zinc Plated

Color: Silver

**Function Specifications****Compatible Wires and Cables**

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):

**Threaded Rods and Bolts**

Tapped Holes:

Clearance Holes (in):

Threaded Rod Size (in):

**Compatible Conduit**

EMT Size (in): 1-1/2

Rigid/IMC (in): 1-1/2

**Compatible Flanges and Studs**

Flange Size (in):

Metal Stud Size (ins):

**Static Load Rating**

Vertical (lbs):

Horizontal (lbs):

**Other**

Suitable for use with standard 1-5/8 strut

**Codes and Regulatory**Regulatory  
Certifications: ASTMA-366, A-575 and A-576 standards

Country of Origin: US

**Packaging**

General Packaging: Cardboard Box

Box Size: 11 X 7.5 X 7.25

Pieces per Package: 50

Other Box Features:

**Document Information**

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11255

Revision Level: 01

ECN #: GAECN01482

Date: 12/10/2013

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[PSK245I](#)