
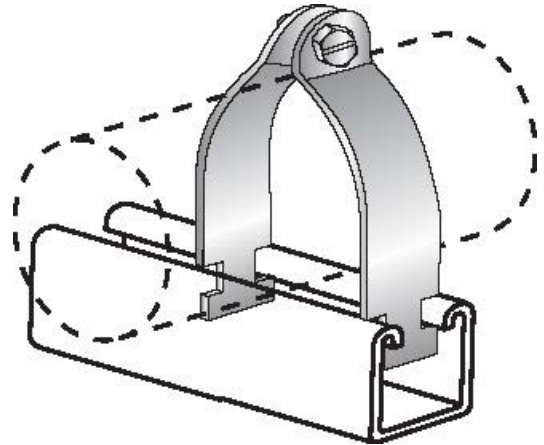


Part Number: PSK405I

Product Description: UNIVERSAL STRUT CLAMP FOR 2-1/2" CONDUIT

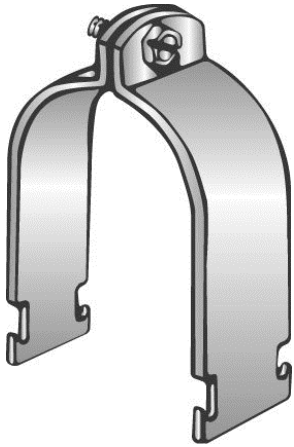

Material Specifications

Type: Hot Rolled, Pickled and Oiled Steel

Finish: Zinc Plated

Color: Silver

Function Specifications

Compatible Wires and Cables

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):

Threaded Rods and Bolts

Tapped Holes:

Clearance Holes (in):

Threaded Rod Size (in):

Compatible Conduit

EMT Size (in): 2-1/2

Rigid/IMC (in): 2-1/2

Compatible Flanges and Studs

Flange Size (in):

Metal Stud Size (ins):

Static Load Rating

Vertical (lbs):

Horizontal (lbs):

Other

Suitable for use with standard 1-5/8 strut

Codes and Regulatory

Regulatory
Certifications: ASTMA-366, A-575 and A-576 standards

Country of Origin: US

Packaging

General Packaging: Cardboard Box

Box Size: 8.25 X 7.25 X 5.75

Pieces per Package: 50

Other Box Features:

Document Information

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11257

Revision Level: 01

ECN #: GAECN01482

Date: 12/10/2013

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[PSK405I](#)