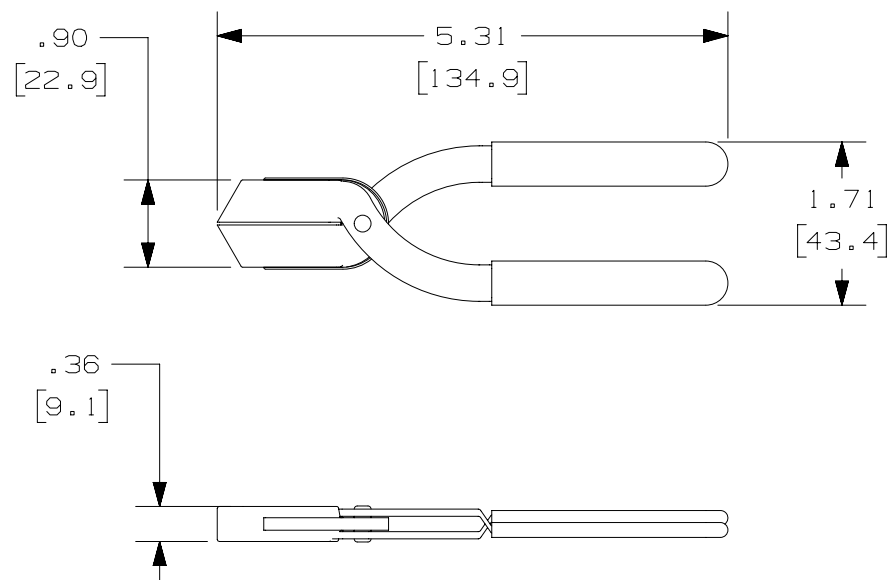



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.


 


| | |
|-------------|--------------------------|
| PANDUIT P/N | WEIGHT |
| FBFSP | .114 LB/EA 51.75 g/EA |

NOTES :

1. SEE CURRENT CATALOG FOR ADDITIONAL PART SUFFIXES TO INDICATE PACKAGE QUANTITY.
2. BUFFER STRIPPERS ARE USED TO STRIP 900um BUFFER OFF OF 125um CLADDING.
3. DIMENSIONS IN PARENTHESES ARE IN METRIC.
4. MINIMUM CUTTING DIAMETER IS 203 MICRONS (.008").

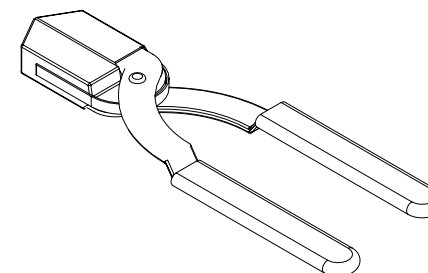

| | | | |
|---|----------|---|--------------------|
| PART NUMBER | | FBFSP | |
| TITLE | | | |
| GLASS OPTICAL FIBER KIT BUFFER STRIPPERS 203 MICRONS | | | |
| CUSTOMER DRAWING | | | |
| ITEM REVISION NAME | |  | |
| D35560EP/00 | | | |
| DATASET FILE NAME | | MATERIAL : DRAWING NUMBER : 35560-93 | |
| D35560EP_DC/00B | | | |
| UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm] .X ± .XXX ± .010 [.3] .XX ± .03 [.8] ANGLES ± | |  THIRD ANGLE PROJECTION | |
| DRAWN BY | DATE | CHK | SIZE |
| JBA | 07-07-97 | CEF | AONE SHT 1 OF 1 |

D10100DA/14

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

FBFSP FBFSPM