


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

NOTES:

1. SEE CURRENT CATALOG FOR VARIOUS APPLICATIONS AND TO INDICATE PACKAGE QUANTITY.
2. 110 CONNECTOR ON ONE END AND AN RJ45 MODULAR PLUG WIRED TO EIA/TIA 568B ON THE OTHER END. THE PATCH CORDS CAN BE USED WITH PAN-PUNCH 110 CONNECTING BLOCKS.
3. 110 CONNECTOR FEATURES INCLUDE A CLEAR CAP TO ENSURE PROPER CONNECTOR ORIENTATION. RETAINING CLIPS SECURE THE JACKET CLOSE TO THE POINT OF TERMINATION WHICH MINIMIZES WIRE UNTWISTING. INTEGRAL STRAIN RELIEF MINIMIZES STRESS ON WIRES DURING DISCONNECTION.
4. POLARIZED TO PREVENT REVERSE INSTALLATION TO CONNECTOR BLOCK.
5. DIMENSIONS IN PARENTHESES ARE IN METRIC.

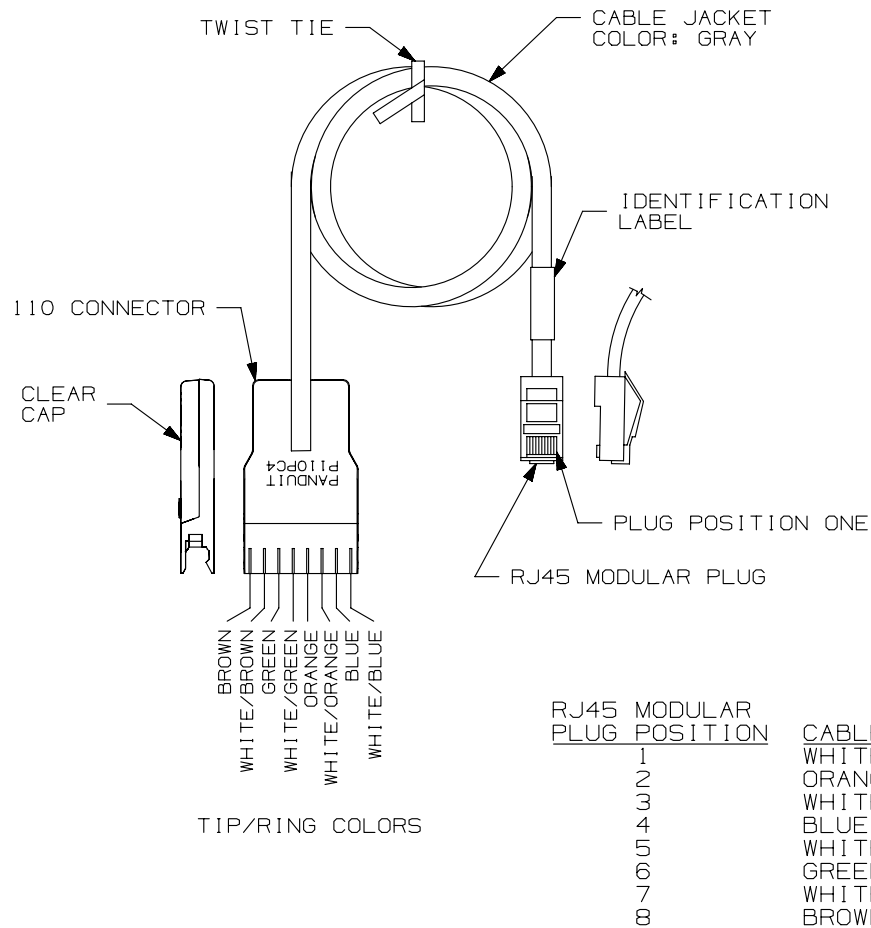

PANDUIT PART NUMBER	MIN. CABLE LENGTH	WEIGHT
P110PC4IG2BY	2 FT.	.71 LB/10 PCS (322 g/10 PCS)
P110PC4IG4BY	4 FT.	1.17 LB/10 PCS (531 g/10 PCS)
P110PC4IG5BY	5 FT.	1.4 LB/10 PCS (635 g/10 PCS)
P110PC4IG6BY	6 FT.	1.63 LB/10 PCS (740 g/10 PCS)
P110PC4IG7BY	7 FT.	1.86 LB/10 PCS (844 g/10 PCS)
P110PC4IG8BY	8 FT.	2.09 LB/10 PCS (948 g/10 PCS)
P110PC4IG9BY	9 FT.	2.32 LB/10 PCS (1053 g/10 PCS)
P110PC4IG12BY	12 FT.	3.01 LB/10 PCS (1366 g/10 PCS)
P110PC4IG15BY	15 FT.	3.7 LB/10 PCS (1679 g/10 PCS)
P110PC4IG1MBY	1 M	.998 LB/10 PCS (452 g/10 PCS)
P110PC4IG2MBY	2 M	1.74 LB/10 PCS (792 g/10 PCS)
P110PC4IG3MBY	3 M	2.49 LB/10 PCS (1131 g/10 PCS)
P110PC4IG5MBY	5 M	3.98 LB/10 PCS (1810 g/10 PCS)

PART NUMBER		P110PC4IG*BY, P110PC4IG*MBY	
TITLE			
PAN-PUNCH 110 PATCH CORD ASSEMBLY			
CUSTOMER DRAWING			
ITEM REVISION NAME		D35536BK_DC09_RJ45/01	
DATASET FILE NAME		D35536BK_DC09_RJ45/01E	
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm]		MATERIAL:	
.X ± .XXX ± .010 [.3]		DRAWING NUMBER:	
.XX ± .03 [.8] ANGLES ±		35536-09	
THIRD ANGLE PROJECTION			
DRAWN BY	DATE	CHK	SCALE
TPC	10-02-96	CEF	NONE
SHT 1 OF 1			SIZE
			A

5	5/28/14	JSP	REFR	MMR	REVISED AND REDRAWN, PREVIOUS REVISIONS HAVE BEEN OMITTED.	35536-09
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[P110PC4IG5MBY](#) [P110PC4IG3MBY](#) [P110PC4IG12BY](#) [P110PC4IG7BY](#) [P110PC4IG4BY](#) [P110PC4IG2BY](#)
[P110PC4IG15BY](#) [P110PC4IG2MBY](#) [P110PC4IG9BY](#) [P110PC4IG6BY](#) [P110PC4IG8BY](#) [P110PC4IG1MBY](#)
[P110PC4IG5BY](#)