


1

NOTES:

1. IDENTIFICATION: VERTICAL, (20) 5-15R, METERED
120V / 15A / SINGLE-PHASE POU

<u>PART NO.</u>	<u>COLOR</u>
CMRPSV15SILM	BLACK

2. ACCESSORY COMPONENTS:
(4) #10-32 x 1/2" MOUNTING SCREWS
(4) #12-24 x 1/2" MOUNTING SCREWS
(2) #10-32 LOCKING COLLAR SCREWS
(2) L-BRACKETS
3. DIMENSIONS IN PARENTHESES ARE METRIC (mm).
4. POWER METER - RED, 4-DIGIT LED CONTINUOUSLY SCROLLS THROUGH POWER FACTOR, AMPS, VOLTS (RMS), AND REAL POWER IN WATTS (RMS).
5. SURGE SUPPRESSION UP TO 330V OR 720 JOULES.
6. UL® & c-UL® LISTED 1950.
7. RoHS COMPLIANT.
8. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART.
9. MAXIMUM AVAILABLE INPUT POWER = 1.4 KW
10. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES.

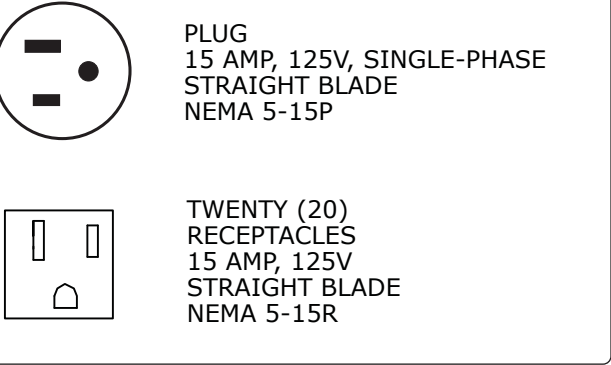

1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[CMRPSV15SILM](#)