


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT PART #	WIRE SIZE AWG [mm ²]		HOUSING COLOR	COLOR RING STEP-DOWN END	DIMENSIONS in. [mm]				WIRE STRIP LENGTH in [mm] +1/32 [0,8] -0	TOOLS	TOOL POCKET
	STANDARD END	STEP-DOWN END			L ± .04 [1.1]	C ± .01 [0.3]	D ± .01 [0.3]	B			
ESV14-ESV18	#16-14 [1,5-2,5]	#22-18 [0,5-0,75]	BLUE	RED	.96 [24.5]	.09 [2.3]	.07 [1.7]	.165 [4.2]	9/32 [6,8]	KST2000A	BLUE #16-14
ESV10-ESV18	#12-10 [4,0-6,0]	#22-18 [0,5-0,75]	YELLOW	RED	1.22 [31.0]	.13 [3.4]	.07 [1.7]	.236 [6.0]			YELLOW #12-10
ESV10-ESV14	#12-10 [4,0-6,0]	#16-14 [1,5-2,5]	YELLOW	BLUE	1.22 [31.0]	.13 [3.4]	.09 [2.3]	.236 [6.0]			YELLOW #12-10
ESV8-ESV14*	#8 [8,0]	#16-14 [1,5-2,5]	RED	BLUE	1.41 [35.7]	.18 [4.5]	.09 [2.3]	.322 [8.2]	3/8 [9,6]	KST-HDC38A	#8 [8,0]
ESV8-ESV10*	#8 [8,0]	#12-10 [4,0-6,0]	RED	YELLOW	1.41 [35.7]	.18 [4.5]	.13 [3.4]	.322 [8.2]			#8 [8,0]
ESV6-ESV8	#6 [14,0]	#8 [8,0]	BLUE	RED	1.77 [45.0]	.23 [5.9]	.18 [4.5]	.401 [10.2]			#6 [14,0]

*NOT UL LISTED

NOTES:

- USED FOR:
 - STRANDED COPPER WIRE ONLY
 - 167°F [75°C] MAX. OPERATING TEMPERATURE
 - 600V MAX VOLTAGE RATING
- MATERIAL:
 - STAMPING: COPPER TUBE, TIN PLATED
 - HOUSING: VINYL
- SEE WWW.PANDUIT FOR PACKAGE QUANTITIES
- DIMENSIONS IN BRACKETS ARE METRIC EQUIVALENT

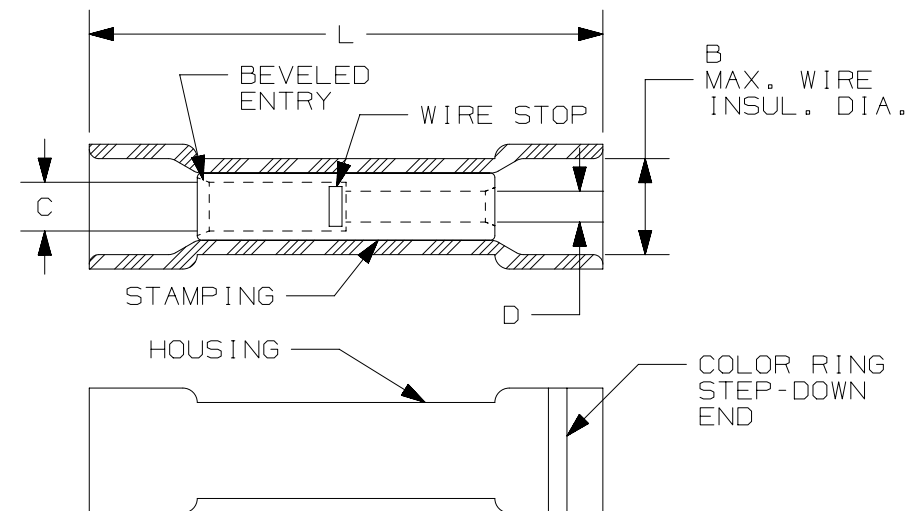

LISTED
2000
E52164

TITLE				
STRONGHOLD STEP-DOWN BUTT SPLICES VINYL INSULATED, #22-6 AWG				
CUSTOMER DRAWING				
ITEM REVISION NAME			PANDUIT	
00123SSD/00				
DATASET FILE NAME			MATERIAL: SEE NOTES	
00123SSD-DC/00				
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm] .x ± .1 [2.54] .xxx ± .005 [.127] .xx ± .01 [.25] ANGLES ± 5°				
DRAWING NUMBER: 00123SSD-DC			THIRD ANGLE PROJECTION	
DRAWN BY	DATE	CHK	SCALE	SIZE
JHNU	-	-	N.T.S.	A

00	2/18	JHNU	TMR	RGB	DRAWING RELEASED	00123SS
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN

B

A

A

B

A

A

B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[ESV6-ESV8-Q](#) [ESV8-ESV10-Q](#) [ESV8-ESV14-Q](#) [ESV10-ESV14-Q](#) [ESV10-ESV18-Q](#) [ESV14-ESV18-Q](#)