
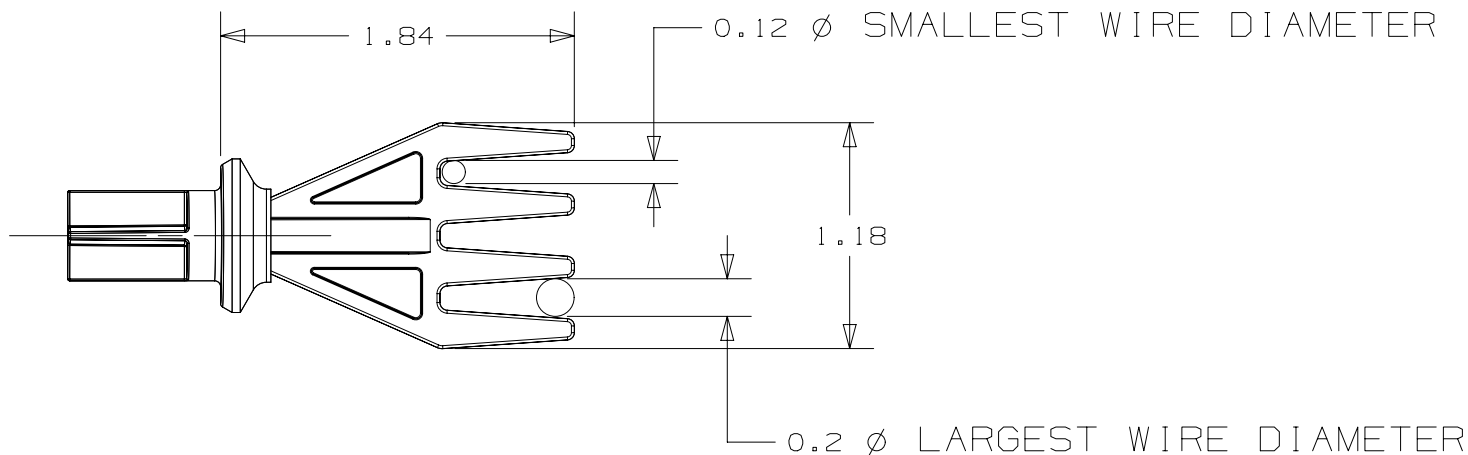


2

1

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

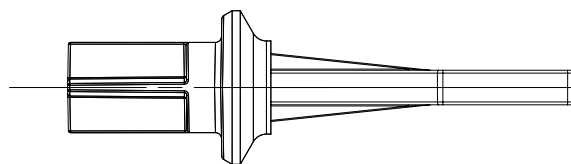

NOTES:

- GRIPS WIRES OF 10-12 GAGE FOR USE WITH QUICK BUILD HARNESS BOARD.
- FOR USE WITH QUICK-BUILD MOUNTING PEG - P/N QB-MOUNT-L.
- SEE CUSTOMER PRICE SHEET FOR PART NUMBER SUFFIX DESIGNATION FOR PACKAGE SIZE.

PRODUCT SPEC		PACKAGING SPEC	
PART NUMBER QB-WEH1012		WORK INSTRUCTION	
INSPECTION INSTRUCTION NUMBER		FMEA & CONTROL PLAN NUMBER	
TITLE QUICK BUILD WIRE END HOLDER			
CUSTOMER DRAWING			
ITEM REVISION NAME 14L203GQ/09		PANDUIT	
DATASET FILE NAME 14L203GQ_DC/09			
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm]		MATERIAL: ABS, YELLOW	
.x ± .1 [2.54] .xxx ± .005 [.127] .xx ± .01 [.25] ANGLES ± 5 °		DRAWING NUMBER: 14L203GQ_DC	
THIRD ANGLE PROJECTION			
DRAWN BY DFA	DATE 10/25/16	CHK JHAC	SCALE NONE
SHT 1 OF 1		A	

0	10/19/16	DFA	CLW	JHAC	INITIAL RELEASE	GAECN03844
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN

2

1

B

A

A

A

D10100DA/20

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[QB-WEH1012-Q](#)