


Fray Resistant Braided Expandable Sleeving

Fray Resistant Braided Expandable Sleeving features an innovative design that resists fraying when cut with scissors and provides superior abrasion resistance once installed. It is ideal for applications requiring an abrasion protection product that will not trap heat or humidity. The open weave design provides flexibility for dynamic applications, while the increased braid density offers added protection. Fray Resistant Braided Expandable Sleeving is part of the complete line of Panduit accessories to bundle and protect cable and wiring.

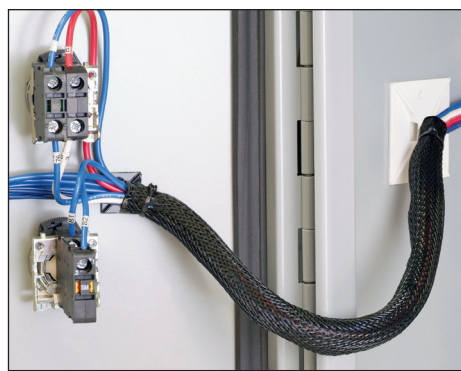

Key Features

Benefits

Innovative, fray resistant design

Resists fraying when cut with scissors, for reduced installation time and cost
Hot knife not required for cutting

Open weave design

Protects cable and wiring without trapping heat or moisture for improved reliability, while providing flexibility in dynamic applications
Accepts greater range of bundle size, reducing inventory required

Increased braid density

Provides continuous abrasion protection

Packaged on a reel

Ensures easy handling and dispensing of product

Fray Resistant Braided Expandable Sleeving

Ordering Information

Fray Resistant Braided Expandable Sleeving

Part Number*‡	Nominal I.D.		Bundle Diameter Range		Length Ft. (m)	Std. Pkg. Qty.	Std. Ctn. Qty.
	In.	mm	In.	mm			
SE12PSC-TR0	0.12	3.2	0.125 to 0.250	3.2 to 6.4	200 (61.0)	1	4
SE25PSC-TR0	0.25	6.4	0.156 to 0.438	4.0 to 11.1	200 (61.0)		
SE38PSC-TR0	0.38	9.5	0.187 to 0.625	4.8 to 15.9	200 (61.0)		
SE50PSC-CR0	0.50	12.7	0.250 to 0.750	6.4 to 19.1	100 (30.5)		
SE75PSC-CR0	0.75	19.1	0.625 to 1.00	15.9 to 25.4	100 (30.5)		
SE125PSC-LR0	1.25	31.8	1.00 to 1.50	25.4 to 38.1	50 (15.2)		
SE150PSC-LR0	1.50	38.1	1.25 to 2.00	31.8 to 50.8	50 (15.2)		

*All product color is black.

‡Reel Packaging may contain splices.

All products are manufactured from a Polyethylene Terephthalate material.

Related Products

Standard Braided Expandable Sleeving

Part Number*‡	Nominal I.D.		Bundle Diameter Range		Length Ft. (m)	Std. Pkg. Qty.	Std. Ctn. Qty.
	In.	mm	In.	mm			
SE12P-TR0	0.12	3.2	0.125 to 0.250	3.2 to 6.4	200 (61.0)	1	4
SE25P-TR0	0.25	6.4	0.156 to 0.438	4.0 to 11.1	200 (61.0)		
SE38P-TR0	0.38	9.5	0.187 to 0.625	4.8 to 15.9	200 (61.0)		
SE50P-CR0	0.50	12.7	0.250 to 0.750	6.4 to 19.1	100 (30.5)		
SE75P-CR0	0.75	19.1	0.625 to 1.00	15.9 to 25.4	100 (30.5)		
SE125P-LR0	1.25	31.8	1.00 to 1.50	25.4 to 38.1	50 (15.2)		
SE150P-LR0	1.50	38.1	1.25 to 2.00	31.8 to 50.8	50 (15.2)		
SE175P-TR0	1.75	44.5	1.25 to 2.75	31.8 to 69.8	200 (61.0)	1	2
SE200P-TR0	2.00	50.8	1.50 to 3.5	38.1 to 88.9	200 (61.0)		
SE250P-TR0	2.50	63.5	1.75 to 3.6	44.5 to 92.3	200 (61.0)		

Flame Retardant Braided Expandable Sleeving

SE12PFR-TR0	0.12	3.2	0.094 to 0.250	2.4 to 6.4	200 (61.0)	1	4
SE25PFR-TR0	0.25	6.4	0.125 to 0.375	3.2 to 9.5	200 (61.0)		
SE38PFR-TR0	0.38	9.5	0.188 to 0.625	4.7 to 15.9	200 (61.0)		
SE50PFR-CR0	0.50	12.7	0.250 to 0.750	6.4 to 19.1	100 (30.5)		
SE75PFR-CR0	0.75	19.1	0.500 to 1.25	12.7 to 31.8	100 (30.5)		
SE125PFR-LR0	1.25	31.8	0.750 to 1.50	19.1 to 38.1	50 (15.2)		
SE150PFR-LR0	1.50	38.1	1.00 to 2.25	25.4 to 57.2	50 (15.2)		
SE175PFR-TR0	1.75	44.5	1.25 to 2.75	31.8 to 69.8	200 (61.0)	1	2

*All products listed are black. For color, replace "0" at the end of the part number with "8" for gray and "10" for white.

‡Reel Packaging may contain splices.

All products are manufactured from a Polyethylene Terephthalate material.

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT CANADA
Markham, Ontario
cs-cdn@panduit.com
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
cs-emea@panduit.com
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
cs-ap@panduit.com
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
cs-japan@panduit.com
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
cs-la@panduit.com
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
cs-aus@panduit.com
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com

Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

PANDUIT®

©2015 Panduit Corp.
ALL RIGHTS RESERVED.
WACB25--WW-ENG
Replaces SA-WACB12
10/2015

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[SE200PFR-TR0](#)