



### GP6™ PLUS Category 6 Connecting Blocks

- Exceed ANSI/TIA-568-C.2 Category 6 standard
- Available in 4 or 5-pair connection blocks
- Highly visible color-coded wiring slots ease wiring
- Can be terminated with single or multiple position punchdown tools
- Can be utilized with discrete wires or GP6™ PLUS Patch Cord Connector
- Constructed of UL 94V-0 high impact polycarbonate material
- Patented single piece robust construction
- Optional 4-pair retaining clip (GPRC4) provides additional conductor retention and minimizes errors during moves, adds, and changes



GPCB4-\*Y



GPCB5-\*Y

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>4-Pair Connecting Block</b>			
<b>GPCB4-XY</b>	4-pair Category 6 punchdown connecting block.	10	1000
<b>GPCB4-CY</b>	4-pair Category 6 punchdown connecting block.	100	1000
<b>5-Pair Connecting Block</b>			
<b>GPCB5-XY</b>	5-pair Category 6 punchdown connecting block.	10	1000
<b>GPCB5-CY</b>	5-pair Category 6 punchdown connection block.	100	1000

Termination tool available on page B.79 of SA-NCCB51.


Cable requirement: terminates most 22 – 26 AWG solid or stranded IWC wire with a 0.050" (1.27mm) max o.d., either PVC or plenum rated.

To ensure optimal performance, Panduit recommends use with other Panduit Category 6 PLUS components.




### GP6™ PLUS Category 6 High Density Bases

- Exceed ANSI/TIA-568-C.2 Category 6 standard
- Ideal for use in cross-connects and consolidation point applications
- Highly visible color-coded wiring slots eases wiring
- Sturdy one-piece design
- Available with or without mounting legs for a variety of mounting options
- Multiple mounting holes available

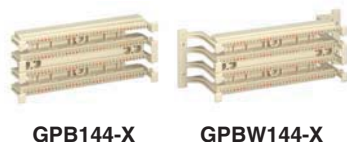

GPB144-X

GPBW144-X

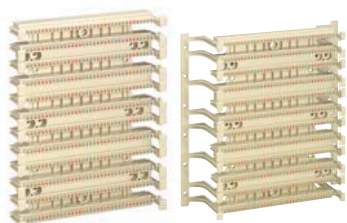

GPB432-X

GPBW432-X

Part Number	Part Description	Std. Pkg. Qty.
<b>144-Pair (36-Port) Base</b>		
<b>GPB144-X</b>	Positions and holds UTP wire for termination with Category 6 punchdown connecting blocks.	10
<b>144-Pair (36-Port) Base – with Legs</b>		
<b>GPBW144-X</b>	Positions and holds UTP wire for termination with Category 6 punchdown connecting blocks, includes mounting legs.	10
<b>432-Pair (108-Port) Base</b>		
<b>GPB432-X</b>	Positions and holds UTP wire for termination with Category 6 punchdown connecting blocks.	10
<b>432-Pair (108-Port) Base – with Legs</b>		
<b>GPBW432-X</b>	Positions and holds UTP wire for termination with Category 6 punchdown connecting blocks, includes mounting legs.	10

Termination tool available on page B.79 of SA-NCCB51.

For rack mount applications see page B.81 of SA-NCCB51.

Cable requirement: terminates most 22 – 26 AWG solid or stranded IWC wire with a 0.050" (1.27mm) max o.d., either PVC or plenum rated.

To ensure optimal performance, Panduit recommends use with other Panduit Category 6 PLUS components.

Can be clearly identified with label holders and recommended labels shown on page C.76 of SA-NCCB51.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[GPCB4-XY](#) [GPBW144-X](#) [GPB432-X](#) [GPBW432-X](#) [GPCB5-XY](#) [GPCB5-CY](#) [GPCB4-CY](#)