
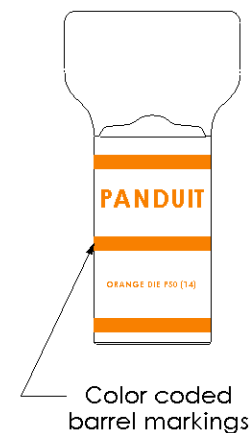
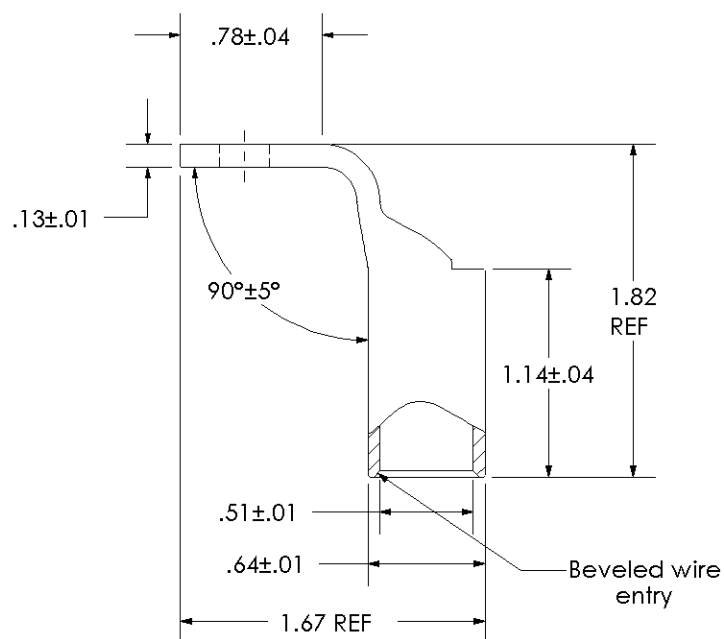


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	3/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-3/16 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	ORANGE
Panduit Die Index No. on Barrel	P50
Alternate Industry Die Index No. () on Barrel	(14)

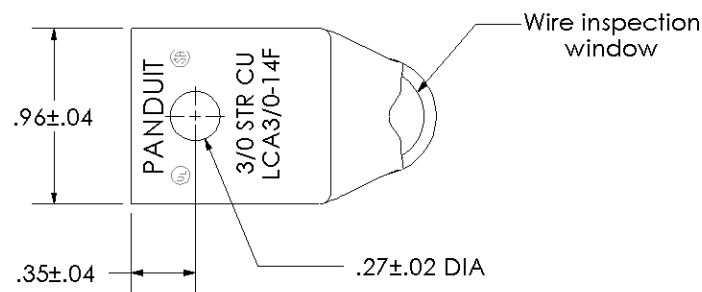

						PANDUIT CORP. TINLEY PARK, ILLINOIS	
						LCA3/0-14F-X	
						Copper Lug - One-Hole, Standard Barrel, 90° Angle Tongue	
01	1/04	DRL	DRL	ADDED UL, CSA AND PART NO. TO STAMP	11431	SCALE N/A	DRAWING NO / CAD FILE
REV	DATE	BY	CHK	DESCRIPTION	ECN	LCA3_0-14F-CUST	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCA3/0-14F-X](#)