



Dot Matrix Labels

Non-Laminated Labels

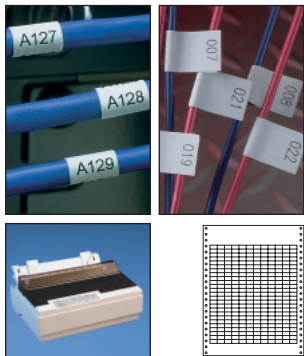

- High quality, economical solution for wire/cable labeling
- Use as a wrap around label or flag style marker for wire/cable labeling
- Available in vinyl cloth material and supplied on 9 pin fed sheets
- *PANDUIT* labeling software packages include all label formats for quick and easy label production

Part Number System for Non-Laminated Labels

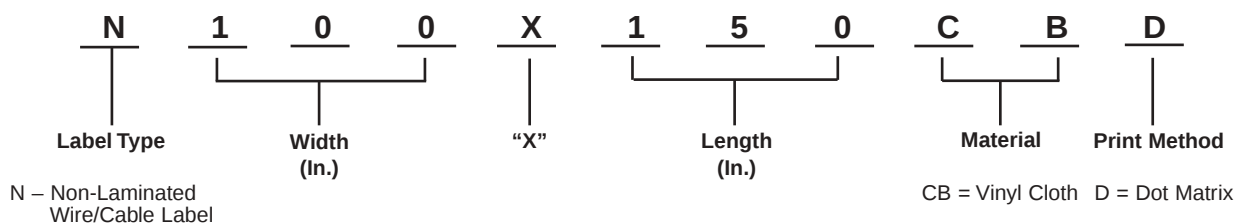

Material/Print Method Selection Guide

Material	Print Method	Temperature Range	Features
Vinyl Cloth, White (CB) •	Dot Matrix (D)	-50°F to 170°F (-46°C to 77°C)	Indoor/outdoor rated; thin conformable material with repositionable adhesive allows label to be removed and reused or used in temporary applications; provides durability, high temperature resistance and dimensional stability for rough or textured surface

•UL Recognized. 

System Overview

Labeling Solutions by Application

Labels by Print Method

Labeling Software

Printers

Pre-Printed and Write-On Markers

Lockout / Tagout

Safety and Facility ID

Generic Order Forms

Standards

Technical Reference/ Index

System
Overview

Dot Matrix Labels

Non-Laminated Labels



Labeling
Solutions
by
Application

Labels
by
Print
Method


Part Number	Part Description	Width		Length		Min. Cable O.D.		Max. Cable O.D.		Std. Pkg. Qty.	Std. Ctn. Qty.
		In.	mm	In.	mm	In.	mm	In.	mm		
N025X075CBD	White, vinyl cloth label	.25	6.35	.75	19.05	.24	6.10	.51	12.95	5000	20000
N025X125CBD	White, vinyl cloth label	.25	6.35	1.25	31.75	.40	10.16	.85	21.59	5000	20000
N025X150CBD	White, vinyl cloth label	.25	6.35	1.50	38.10	.48	12.19	1.02	25.91	5000	20000
N025X175CBD	White, vinyl cloth label	.25	6.35	1.75	44.45	.56	14.22	1.19	30.23	5000	20000
N050X075CBD	White, vinyl cloth label	.50	12.70	.75	19.05	.24	6.10	.51	12.95	5000	15000
N050X125CBD	White, vinyl cloth label	.50	12.70	1.25	31.75	.40	10.16	.85	21.59	5000	20000
N050X150CBD	White, vinyl cloth label	.50	12.70	1.50	38.10	.48	12.19	1.02	25.91	5000	10000
N050X175CBD	White, vinyl cloth label	.50	12.70	1.75	44.45	.56	14.22	1.19	30.23	5000	10000
N100X075CBD	White, vinyl cloth label	1.00	25.40	.75	19.05	.24	6.10	.51	12.95	5000	20000
N100X125CBD	White, vinyl cloth label	1.00	25.40	1.25	31.75	.40	10.16	.85	21.59	5000	20000
N100X150CBD	White, vinyl cloth label	1.00	25.40	1.50	38.10	.48	12.19	1.02	25.91	5000	15000
N100X175CBD	White, vinyl cloth label	1.00	25.40	1.75	44.45	.56	14.22	1.19	30.23	5000	15000

Order number of labels required in multiples of Std. Pkg. Qty.

Labeling
Software

Printers

Flag Style Labels

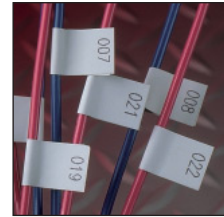

Pre-Printed
and
Write-On
Markers

Lockout/
Tagout

Part Number	Part Description	Width		Length		Min. Cable O.D.		Max. Cable O.D.		Std. Pkg. Qty.	Std. Ctn. Qty.
		In.	mm	In.	mm	In.	mm	In.	mm		
N025X150CBD	White, vinyl cloth label	.25	6.35	1.50	38.10	.48	12.19	1.02	25.91	5000	20000
N025X175CBD	White, vinyl cloth label	.25	6.35	1.75	44.45	.56	14.22	1.19	30.23	5000	20000
N050X150CBD	White, vinyl cloth label	.50	12.70	1.50	38.10	.48	12.19	1.02	25.91	5000	10000
N050X175CBD	White, vinyl cloth label	.50	12.70	1.75	44.45	.56	14.22	1.19	30.23	5000	10000
N100X150CBD	White, vinyl cloth label	1.00	25.40	1.50	38.10	.48	12.19	1.02	25.91	5000	15000
N100X175CBD	White, vinyl cloth label	1.00	25.40	1.75	44.45	.56	14.22	1.19	30.23	5000	15000

Order number of labels required in multiples of Std. Pkg. Qty.

Generic
Order
Forms

Standards

Technical
Reference/
Index

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[N050X075CBD](#) [N100X150CBD](#) [N025X125CBD](#) [N025X075CBD](#) [N100X075CBD](#)