


Search within category

GO

BUY NOW

DESIGN / INSTALL

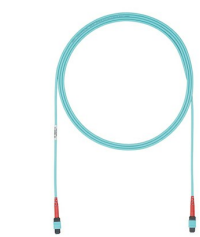

FXURLENXNM027

OM3 24-fiber, Interconnect, LSZH, 24F MPO Female to 24F MPO Female, Method A, Optimized IL, 27 m, Aqua.

Specs	Packaging Details	Documents	★ Add to Favorites	🛒 Add to BOM
Application	Data centers requiring quick infrastructure deployment with extended reach that want to maintain bandwidth throughout the infrastructure.			
Assembly Length Range	20-29 m (66-98 ft)			
Cable Color	Aqua			
Connector 1 Type	24F MPO			
Connector 2 Type	24F MPO			
Fiber Count	24			
Fiber Type	OM3			
Flammability Rating	Low Smoke Zero Halogen (LSZH)			
Length (ft.)	88.56			
Length (m)	27.00			
Standards	TIA/EIA-598-C.3, Plenum Rated NFPA-262, LSZH-Rated, Meet IEC-60332, RoHS Compliant			
RoHS Compliancy Status	Compliant			
Min. Order Qty.	1.0000			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[FXURLENENXNM027](#)