




Search within category

GO

BUY NOW

DESIGN / INSTALL

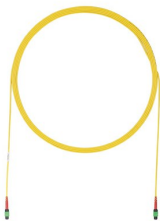

F9URPENENANF017

OS2 24-fiber, Interconnect, Plenum, 24F MPO Female to 24F MPO Female, Method A, Std IL, 17 ft, Yellow.

Specs

Packaging Details

Documents

★ Add to Favorites

🛒 Add to BOM

| | |
|------------------------|---|
| Assembly Length Range | 0-9 m (0-32 ft) |
| Cable Color | Yellow |
| Connector 1 Type | 24F MPO |
| Connector 2 Type | 24F MPO |
| Fiber Count | 24 |
| Fiber Type | OS2 |
| Flammability Rating | Plenum (OFNP) |
| Length (ft.) | 17.00 |
| Length (m) | 5.18 |
| Standards | TIA/EIA-598-C.3, Plenum Rated NFPA-262, LSZH-Rated, Meet IEC-60332, RoHS Compliant |
| RoHS Compliancy Status | Compliant |
| Min. Order Qty. | 1.0000 |
| Application | Data centers requiring quick infrastructure deployment with extended reach that want to maintain bandwidth throughout the infrastructure. |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[F9URPENENANF017](#)