


Search within category

GO

BUY NOW

DESIGN / INSTALL

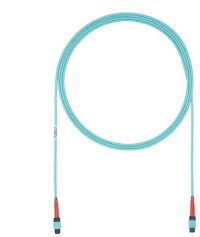

FZURPENENYNF100

OM4 24-fiber, Interconnect, Plenum, 24F MPO Female to 24F MPO Female, Method B, Optimized IL, 100 ft, Aqua.

Specs	Packaging Details	Documents	★ Add to Favorites	🛒 Add to BOM
Application	Data centers requiring quick infrastructure deployment with extended reach that want to maintain bandwidth throughout the infrastructure.			
Assembly Length Range	30-39 m (98-130 ft)			
Cable Color	Aqua			
Connector 1 Type	24F MPO			
Connector 2 Type	24F MPO			
Fiber Count	24			
Fiber Type	OM4			
Flammability Rating	Plenum (OFNP)			
Length (ft.)	100			
Length (m)	30.49			
Standards	TIA/EIA-598-C.3, Plenum Rated NFPA-262, LSZH-Rated, Meet IEC-60332, RoHS Compliant			
RoHS Compliancy Status	Compliant			
Min. Order Qty.	1.0000			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[FZURPENENYNF100](#)