
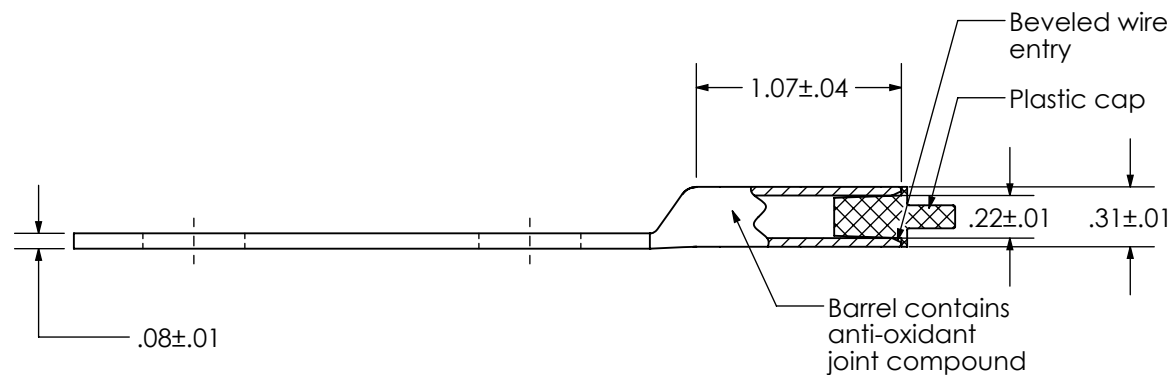


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Coating	Clear Coating
Wire Size	6 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. UL Listed per UL467 for grounding and bonding and suitable for direct burial in earth or concrete.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P24
Alternate Industry Die Index No. () on Barrel	(7)

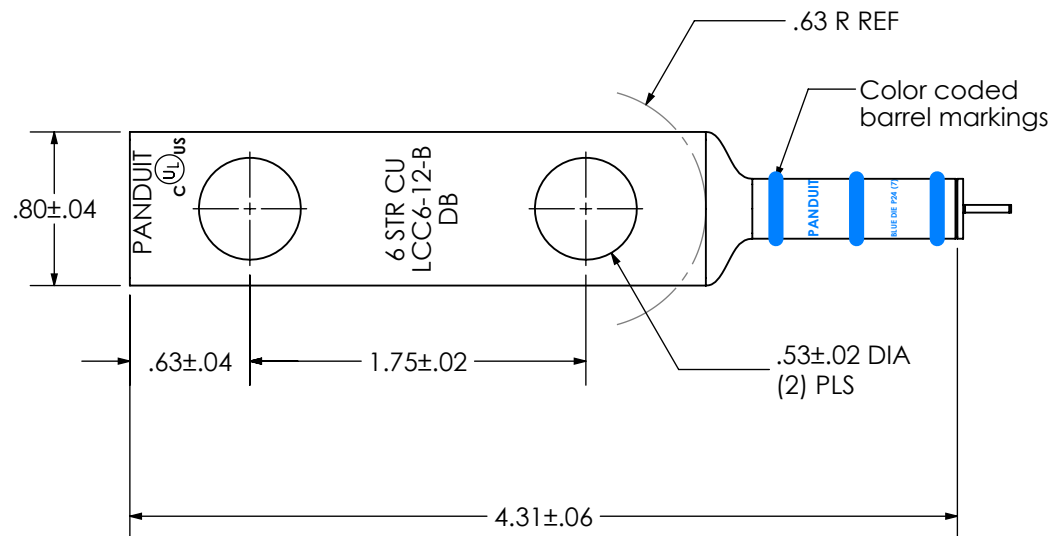

**DB
RATED**

								PANDUIT CORP. TINLEY PARK, ILLINOIS			
								LCC6-12-B-L Copper Lug - Two-Hole, Long Barrel, Direct Burial			
00	3/16	JHNU	RGB	DRAWING RELEASED	00076FBA-LCC6-12-B-CUST	RGB	RGB	SCALE	N/A	DRAWING NO / CAD FILE	LCC6-12-B-CUST
REV	DATE	BY	CHK	DESCRIPTION	ECN	-R	SUP				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

LCC6-12-B-L