



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	350 STR/FLEX
Wire Type	Stranded Copper: Class G, H, I, K, M, Locomotive
Wire Strip Length	1-13/16 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P76
Alternate Industry Die Index No. () on Barrel	(19)

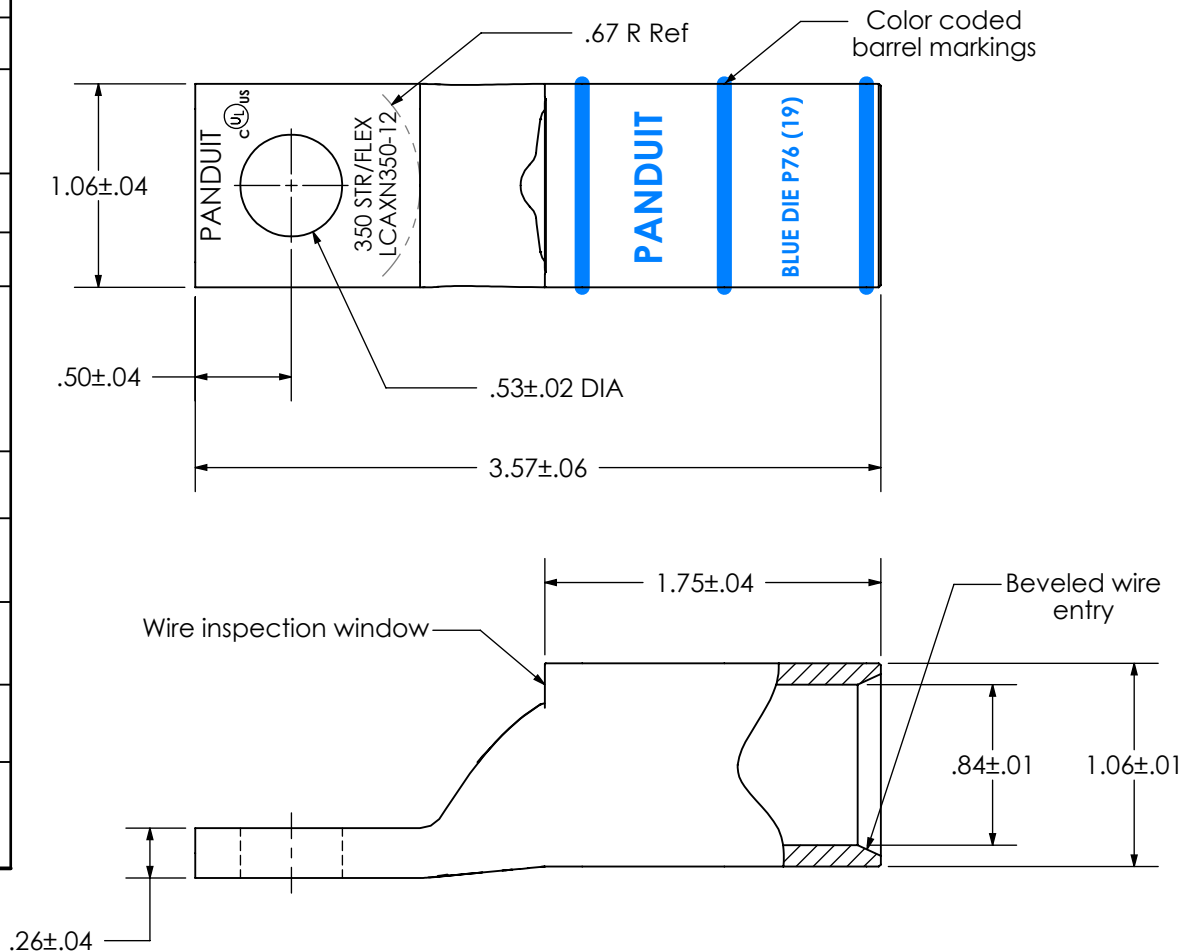

							 PANDUIT CORP. TINLEY PARK, ILLINOIS	
							LCAXN350-12-6 Copper Lug - One-Hole, Narrow Tongue, Standard Flex Barrel	
00	12/16	JHNU	JHNU	RGB	DRAWING RELEASED	00159NCB-LCAXN350-12-CUST		
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCAXN350-12-CUST

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCAXN350-12-6](#)