
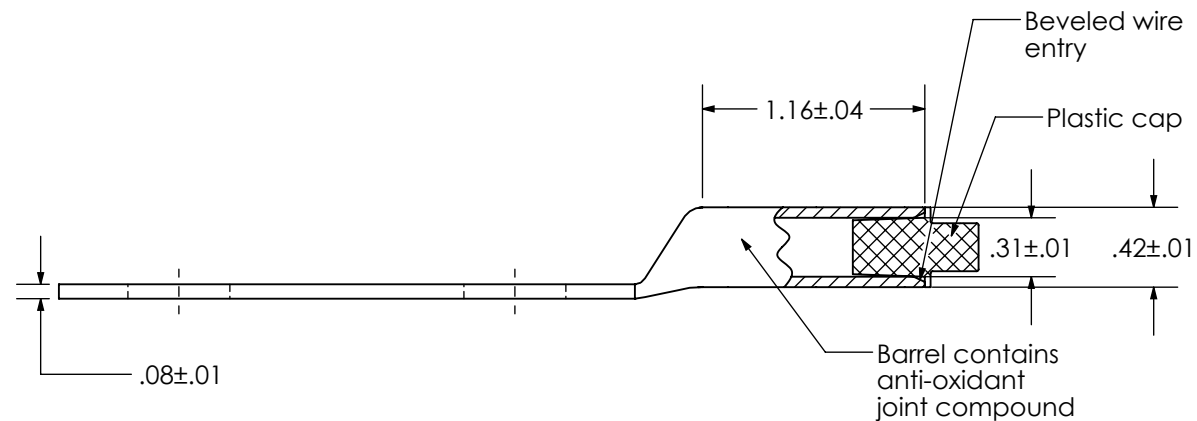


Material	High Conductivity Seamless Copper Tube
Coating	Clear Coating
Wire Size	2 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/4 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.  UL Listed per UL467 for grounding and bonding and suitable for direct burial in earth or concrete.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P33
Alternate Industry Die Index No. ( ) on Barrel	(10)

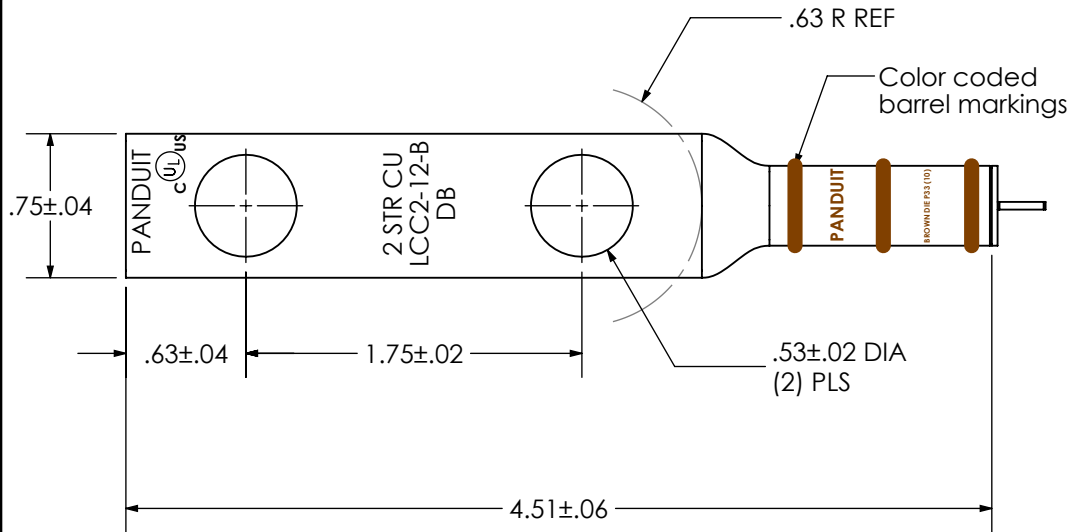

**DB**   
**RATED**

								PANDUIT CORP. TINLEY PARK, ILLINOIS
								LCC2-12-B-Q Copper Lug - Two-Hole, Long Barrel, Direct Burial
00	3/16	JHNU	RGB	DRAWING RELEASED	00076FBB-LCC2-12-B-CUST	RGB	RGB	
REV	DATE	BY	CHK	DESCRIPTION	ECN	-R	SUP	SCALE N/A DRAWING NO / CAD FILE LCC2-12-B-CUST

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCC2-12-B-Q](#)