



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4 AWG, 3 AWG & 2 SOL
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	7/8 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	GRAY
Panduit Die Index No. on Barrel	P29
Alternate Industry Die Index No. ( ) on Barrel	(8)

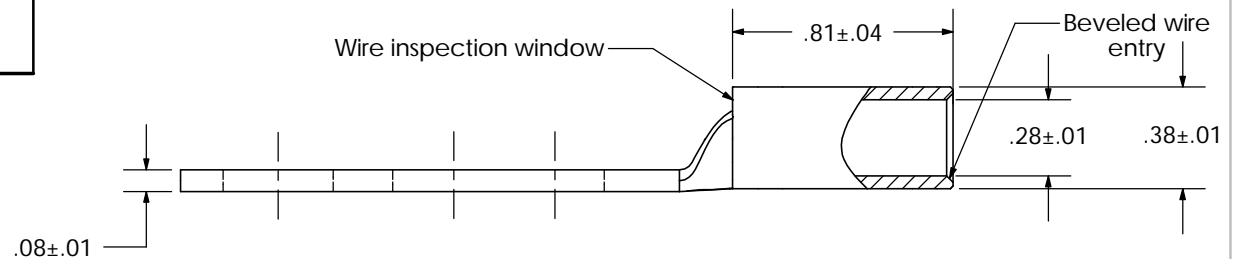

LISTED  
Wire Connector

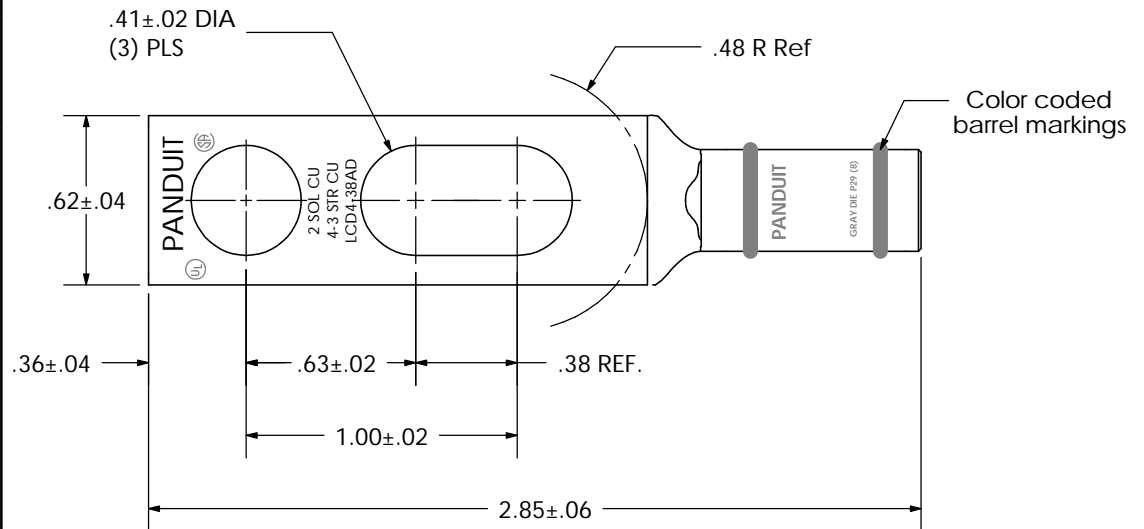

**PANDUIT CORP.** TINLEY PARK, ILLINOIS

LCD4-38AD-L  
Copper Lug - Two-Hole Slotted, Standard Barrel

01	10/05	JHNU	JHNU	ADDED 2 SOL AS STAMPING LINE ON TONGUE	PC00168
REV	DATE	BY	CHK	DESCRIPTION	ECN

SCALE  
N/A

DRAWING NO / CAD FILE  
LCD4-38AD-CUST

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCD4-38AD-L](#)