



STPKCH7MOR

Share

Keyed Copper Patch Cord

Keyed, Category 5e, shielded patch cord with Pan-Plug™ Keyed Shielded Modular Plug on one end and Pan-Plug™ Non-Keyed Shielded Modular Plug on the other end, Orange, 7 meters.

Find A Distributor

Qty

Add to Bom



- Specifications
- Packaging Detail
- Resources
- Related Products
- Top of Page

Specifications

Conductor Gauge (AWG)	26
Conductor Gauge (kcmil)	NA
Performance Level	Category 5e
Conductor Type	Stranded
Connector 2 Type	RJ45 8(8)
Connector 1 Type	RJ45 8(8)
Overall Length (in.)	NA
Overall Length (ft.)	22.97
Overall Length (m)	7
Overall Length (mm)	NA
Nominal Diameter (mm)	NA
Wiring Scheme	TS68A
Maximum Operating Temperature (°C)	60
Maximum Operating Temperature (°F)	140
Minimum Operating Temperature (°C)	-10
Minimum Operating Temperature (°F)	14
Maximum Storage Temperature (°C)	70
Maximum Storage Temperature (°F)	158
Minimum Storage Temperature (°C)	-40
Minimum Storage Temperature (°F)	-40
Boot Color	Orange
Color	International Gray
Sub Brand	PanNet
Flammability Rating	CM, LSZH-1 (60332-1)
Standards Met	ANSI/TIA-568-C.2, ISO 11801 Class EA, IEEE 802.3af, 802.3at, 802.3bt type 3 and type 4, UL 1863.
Product Type	Keyed Copper Patch Cord
Cable Color	International Gray
Length (ft.)	22.97
CE Compliant	Yes
Maximum Installation Temperature (°F)	158
Termination End 1	Keyed Modular Plug
Termination End 2	Non-Keyed Modular Plug
Cable Length (ft.)	22.97
Cable Type	F/UTP
Conductor Material	Copper
Maximum Installation Temperature (°C)	70
Minimum Installation Temperature (°C)	70
Minimum Installation Temperature (°F)	-40
RoHS Compliancy Status	Compliant
Min. Order Qty.	1
Measurement System	Meters (Rest of World)


Packaging Detail

UPC	07498336189
Std. Pkg. Qty.	1
Std. Pkg. Volume (cf)	0.0451
Std. Ctn. Qty.	10
Std. Ctn. Volume (cf)	0.4514

Resources


Line Cards	Network Infrastructure Security Solutions Line Card: COLC07--SA-ENG	US English	View PDF (2.09MB)	Download PDF	Share PDF
------------	---	------------	-------------------	--------------	-----------

Related Products

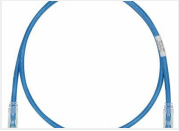


UTPSP7BUY

Category 6, UTP patch cord with TX6™ PLUS Modular Plugs on each end. Blue, 7 ft.

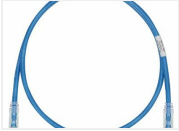

UTPSP2MBUY

 Category 6, UTP patch cord with TX6™ PLUS Modular Plugs on each end. Blue, 2 meters.



UTPSP5BUY

Category 6, UTP patch cord with TX6™ PLUS Modular Plugs on each end. Blue, 5 ft.

Email Support
Email support available 24/7

800-777-3300
Monday through Thursday 7:00 am-6:30 pm
CST Friday 7:00 am-6:00 pm CST

Where to Buy
Find a Panduit Distributor or Partner

About Us
Research and Development
Awards
Partner Ecosystem
World Headquarters

Company Profile
Media Resources
Case Studies
Panduit Code of Conduct

Careers at Panduit
The Hub – Partner Portal
Product Registration
Panduit Connections Blog

Get Our Catalog
Download the PDF or request a copy be mailed to you.

Which catalog would you like? Download

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[STPKCH7MOR](#)