



|  |  |
|--|--|
| Material   | High Conductivity<br>Seamless Copper Tube  |
| Plating  | Electro-Tin  |
| Wire Size  | 1/0 AWG  |
| Wire Type  | Stranded Copper; Class B:<br>Compact, Compressed or<br>Concentric, Class C: Concentric   |
| Wire Strip Length                                    | 1.0 in.  |
| Stud Size  | N/A  |
| UL Listed Wire<br>Connector                          | Yes, for applications up to 35kv.<br>Consult cable manufacturer for<br>voltage stress relief instructions<br>with applications greater than<br>2000 volts. |
| UL Temperature<br>Rating                             | 90° C  |
| C.S.A Certified<br>Wire Connector                    | Yes  |
| Panduit Color Code<br>on Barrel                      | PINK   |
| Panduit Die Index No.<br>on Barrel                   | P42  |
| Alternate Industry<br>Die Index No. ( )<br>on Barrel | (12)   |

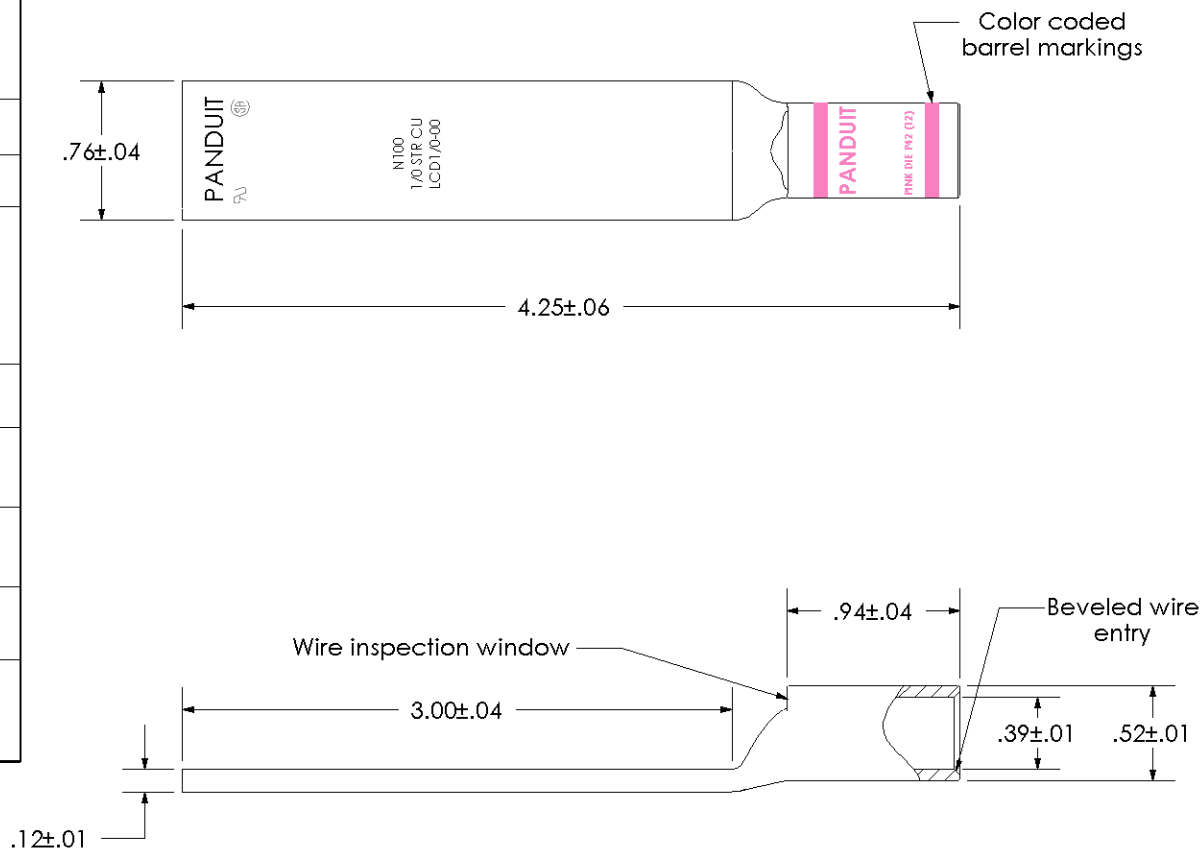

|            |             |           |            |                    |            |  |  |
|------------|-------------|-----------|------------|--------------------|------------|--|--|
|            |             |           |            |                    |            |  <b>PANDUIT CORP. TINLEY PARK, ILLINOIS</b> |  |
|            |             |           |            |                    |            | LCD1/0-00-X<br>Copper Lug - Blank Tongue, Standard Barrel  |  |
| 00         | 12/02       | SAB       | DRL        | RELEASED           | 10343      |  |  |
| <b>REV</b> | <b>DATE</b> | <b>BY</b> | <b>CHK</b> | <b>DESCRIPTION</b> | <b>ECN</b> | <b>SCALE</b><br>N/A  | <b>DRAWING NO / CAD FILE</b><br>LCD1_0-00-CUST |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCD1/0-00-X](#)