


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	750 STR/FLEX
Wire Type	Stranded Copper: Locomotive
Wire Strip Length	1-3/4 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	YELLOW
Panduit Die Index No. on Barrel	P115
Alternate Industry Die Index No. () on Barrel	(L115)

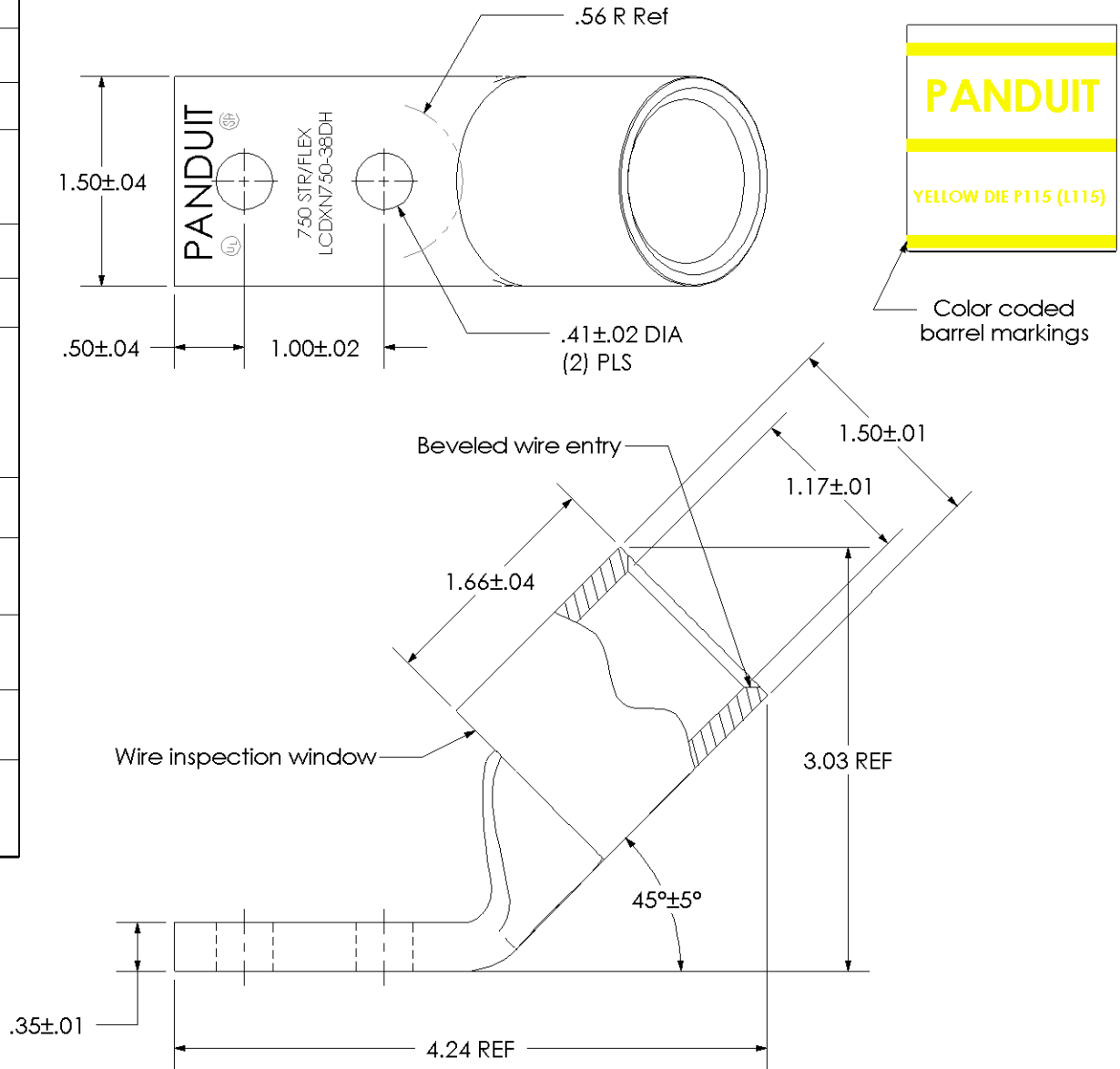

01	8/05	KLFU	KLFU	TONGUE THICKNESS WAS .322	PC00105
REV	DATE	BY	CHK	DESCRIPTION	ECN

		TINLEY PARK, ILLINOIS	
		LCDXN750-38DH-3 Copper Lug - Two-Hole Narrow Tongue, Standard Flex Barrel, 45° Angle Tongue	
SCALE N/A		DRAWING NO / CAD FILE LCDXN750-38DH-CUST	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCDXN750-38DH-3](#)