

FCC5-A-D8 [Share](#)

Flat Cable Mount

Flat cable clips, any width flat cable, .56" (14.2mm) width, gray, bulkpackage.

[Find A Distributor](#)

Qty

Add to Bm

Specifications

Application	Any Width Flat Cable
Product Type	Flat Cable Mount
Adhesive Material	Rubber
Material	PVC
Color	Gray
Environment	Indoor
For Use With	Flat Tubing
Mount Method	Rubber Adhesive Tape
Overall Height (in.)	0.28
Overall Height (mm)	7.1
Overall Length (in.)	1
Overall Length (mm)	25.4
Overall Width (in.)	0.59
Overall Width (mm)	14.8
Standards Met	UL Recognized: E136577; RoHS Compliant
Static Load Capacity (Kg)	0.1
Static Load Capacity (lb)	0.25
UL Recognized	E136577
Cable Width (in.)	0.56
Cable Width (mm)	14.2
Max. Static Load (g)	113.0
Type	Flat Cable Clips
Pricing Category 1	ACB
Pricing Category 2	ACB2

Packaging Detail

UPC	07498359323
Std. Pkg. Qty.	500
Std. Pkg. Volume (cf)	0.0836
Std. Ctn. Qty.	5000
Std. Ctn. Volume (cf)	0.8361

Resources


Part Drawings	GB0239BI	English	View PDF (57.70KB)	Download PDF	Share PDF
Part Drawings	Flat Cable Clip FCC5-A: STP File	English	View STP (61.40KB)	Download STP	Share STP

Related Products




CH105-A-C14

Adhesive backed cable holder, 2.5" (63.5mm) cable width, gray, standard package.

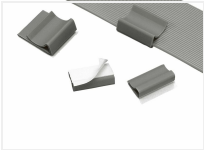

FCC-A-C8

Flat cable clips, any width flat cable, 1.09" (27.7mm) width, gray, standard package.

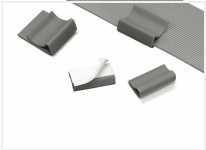

FCC5-A-C8

Flat cable clips, any width flat cable, .56" (14.2mm) width, gray, standard package.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panduit:](#)

[FCC5-A-D8](#)