
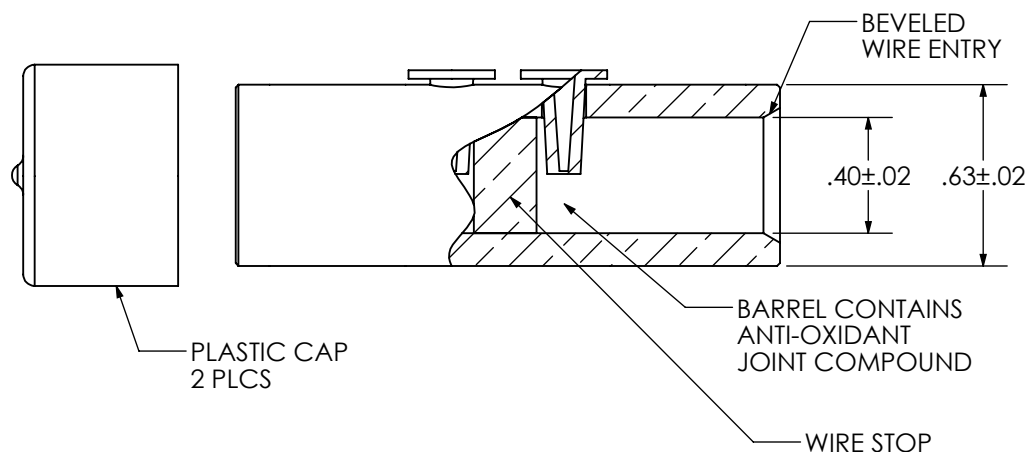


Material	High Conductivity Seamless Copper Tube
Plating	Clear Coated
Wire Size	1/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	7/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.  UL Listed per UL467 for grounding and bonding and suitable for direct burial in earth or concrete.
UL Temperature Rating	90°C
C.S.A. Certified Wire Connector	N/A
Panduit Color Code on Barrel	Orange
Panduit Die Index No. on Barrel	P50
Alternate Industry Die Index No. ( ) on Barrel	(14)

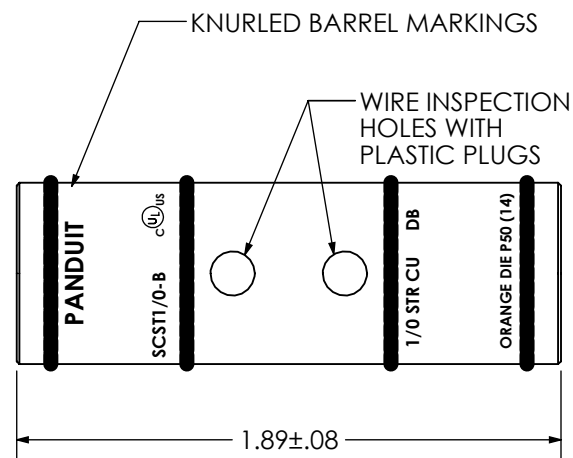

								PANDUIT CORP.	TINLEY PARK, ILLINOIS
				DRAWING RELEASED	NPI-PWRGRD-038781	RGB	RGB	SCST1/0-B-X Copper Butt Splice - Standard Barrel, Direct Burial	
REV	DATE	BY	CHK	DESCRIPTION	ECN	-R	SUP	SCALE N/A	DRAWING NO / CAD FILE SCST1_0-B-CUST

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[SCST1/0-B-X](#)