

Cable connector - ST-17S1G8A8K15S - 1618512

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable connector, straight, SPEEDCON locking, number of positions: 17, cable diameter range: 11 mm ... 12.7 mm, Insulating body color: green



Key Commercial Data

Packing unit	30 pc
GTIN	 4 046356 791472
GTIN	4046356791472


Technical data

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"


Drawings

Schematic diagram

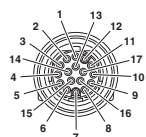

Connector pin assignment

Dimensional drawing

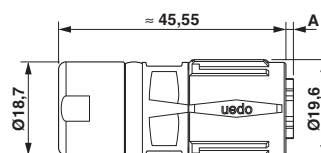

Approvals

Approvals

Cable connector - ST-17S1G8A8K15S - 1618512

Approvals

Approvals

UL Recognized / cUL Recognized / EAC / cULus Recognized

Ex Approvals

Approval details

UL Recognized			http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 335019
Nominal voltage UN		60 V		
Nominal current IN		1 A		
mm²/AWG/kcmil		26		

cUL Recognized			http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 335019
Nominal voltage UN	60 V			
Nominal current IN	1 A			
mm²/AWG/kcmil	26			

EAC		B.01742
-----	---	---------

cULus Recognized	
------------------	---

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1618512](#)