

RJ45 socket insert - VS-08-BU-RJ45/KA/LSA - 1689459

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



RJ45 socket insert, modular (Keystone), CAT5e, 8-pos., shielded, with cable connection (LSA), for solid wires AWG 26 ... 22



Key Commercial Data

Packing unit	5 pc
GTIN	 4 017918 893804
GTIN	4017918893804

Technical data

Mechanical characteristics

Number of positions	8
Number of slots	1
Shielded	yes
Insertion/withdrawal cycles	≥ 750
Connection method	LSA
Conductor cross section	0.13 mm ² ... 0.32 mm ² (solid)
Connection cross section AWG	26 ... 22 (solid)
Degree of protection	IP20

Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
---------------------------------	------------------

Material data

Flammability rating according to UL 94	V0
Contact material	Copper alloy
Contact surface material	Gold over nickel

Electrical characteristics

Number of positions	8
---------------------	---

RJ45 socket insert - VS-08-BU-RJ45/KA/LSA - 1689459

Technical data

Electrical characteristics

 
Transmission characteristics (category)	CAT5 (IEC 11801:2002)
Rated current	1.5 A
Overvoltage category	II
Degree of pollution	2

Standards and Regulations


Flammability rating according to UL 94	V0
--	----

Drawings

Schematic diagram



Dimensional drawing

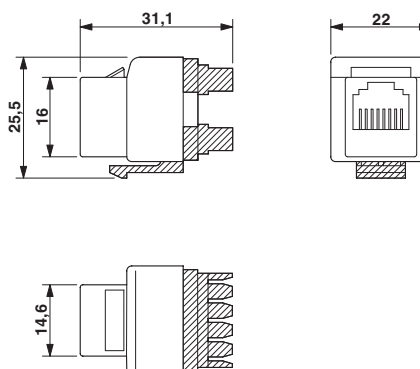

RJ45 socket insert, keystone

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1689459](#)