

## Protective covers - HC-B 24-TMB-SD-IP65-OLOGO - 1691094

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Protective cover IP65, for panel mounting side, with bayonet locking and retaining cord, B24, without logo



### Key Commercial Data

|              |                                                                                                       |
|--------------|-------------------------------------------------------------------------------------------------------|
| Packing unit | 10 pc                                                                                                 |
| GTIN         | <br>4 017918 987251 |
| GTIN         | 4017918987251                                                                                         |

### Technical data

#### Dimensions

|        |         |
|--------|---------|
| Height | 31.2 mm |
| Width  | 55 mm   |
| Length | 150 mm  |

#### Ambient conditions

|                                      |                   |
|--------------------------------------|-------------------|
| Degree of protection of housing (IP) | IP65              |
| Ambient temperature (operation)      | -40 °C ... 125 °C |

#### General

|                                        |                                 |
|----------------------------------------|---------------------------------|
| Size                                   | B24                             |
| Type                                   | HC-ADVANCE protective cover     |
| Housing type                           | Protective cover                |
| Color                                  | gray                            |
| Locking type                           | Bayonet locking                 |
| Seal material                          | NBR                             |
| Material lock                          | High-grade steel, handle: PA-GF |
| Material, protective cover             | PA                              |
| Flammability rating according to UL 94 | V0                              |

#### Standards and Regulations

|                                        |    |
|----------------------------------------|----|
| Flammability rating according to UL 94 | V0 |
|----------------------------------------|----|


#### Environmental Product Compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Protective covers - HC-B 24-TMB-SD-IP65-OLOGO - 1691094

### Drawings

Dimensional drawing

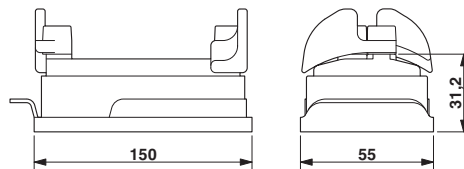

Dimensional drawing

---

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1691094](#)