

## Electrical crimping tool - CF CRIMPHANDY 1,5 - 1212466

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Portable hand-held device, battery-powered, for processing 1.5 mm<sup>2</sup> taped ferrules with function end, suitable for PVC insulated conductors (H07V-K), incl. battery, charger, CUTFOX 12 cable cutter, service tool for troubleshooting, and one 1.5 mm<sup>2</sup> strip of ferrules, packed in a robust case.

### Your advantages

- ✓ The product innovation for switchgear manufacturing – the CRIMPHANDY. You can strip and crimp your conductors in under two seconds using this portable hand-held machine. This step takes 75% less time than before.
- ✓ Consistently optimum results thanks to automatic monitoring functions
- ✓ Unlimited mobile use thanks to battery operation and magazine



### Key Commercial Data

|              |                                                                                                         |
|--------------|---------------------------------------------------------------------------------------------------------|
| Packing unit | 1 pc                                                                                                    |
| GTIN         | <br>4 046356 589154 |
| GTIN         | 4046356589154                                                                                           |

### Technical data

#### Dimensions

|                               |                   |
|-------------------------------|-------------------|
| Length (b)                    | 205 mm            |
| Width (a)                     | 43 mm             |
| Height (c)                    | 70 mm             |
| Conductor diameter area (GRP) | 2.4 mm ... 3.1 mm |
| Stripping length              | 10.8 mm           |

#### General

|                          |              |
|--------------------------|--------------|
| Color                    | black        |
| Compression              | Square crimp |
| Type of contact          | Ferrules     |
| Power consumption        | 20 W         |
| Conductor type           | PVC H07V-K   |
| Maximum stripping length | 10.8 mm      |

# Electrical crimping tool - CF CRIMPHANDY 1,5 - 1212466

## Technical data

### General

|                          |         |
|--------------------------|---------|
| Insertion length minimum | 32 mm   |
| Weight                   | 0.43 kg |
| Min. cross section       | 1.5 mm² |
| Max. cross section       | 1.5 mm² |

### Environmental Product Compliance

|            |                                                                                                     |
|------------|-----------------------------------------------------------------------------------------------------|
| REACH SVHC | Lead 7439-92-1                                                                                      |
| China RoHS | Environmentally Friendly Use Period = 25;                                                           |
|            | For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration" |

## Classifications

### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 17130101 |
| eCl@ss 4.0    | 21040300 |
| eCl@ss 4.1    | 21040300 |
| eCl@ss 5.0    | 21040300 |
| eCl@ss 5.1    | 17130100 |
| eCl@ss 6.0    | 17130100 |
| eCl@ss 7.0    | 17130101 |
| eCl@ss 8.0    | 17130101 |
| eCl@ss 9.0    | 17130101 |

### ETIM

|          |          |
|----------|----------|
| ETIM 4.0 | EC000163 |
| ETIM 5.0 | EC002778 |
| ETIM 6.0 | EC002778 |
| ETIM 7.0 | EC002778 |

### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 27112118 |
| UNSPSC 7.0901 | 27111518 |
| UNSPSC 11     | 23171604 |
| UNSPSC 12.01  | 27111518 |
| UNSPSC 13.2   | 27111518 |
| UNSPSC 18.0   | 27111518 |
| UNSPSC 19.0   | 27111518 |
| UNSPSC 20.0   | 27111518 |
| UNSPSC 21.0   | 27111518 |

## Electrical crimping tool - CF CRIMPHANDY 1,5 - 1212466

### Approvals

#### Approvals

---

Approvals

EAC

---

Ex Approvals

---

#### Approval details

EAC



RU C-  
DE.AI30.B.01549

### Accessories

#### Accessories

##### Assembly tool

Tool - CF CRIMPHANDY 1,5/SERVICE-TOOL - 1212708



Service tool, for CF-CRIMPHANDY 1,5, for rectifying malfunctions

---

Replacement part - CF CRIMPHANDY 1,5/GP2 - 1212844



Waste guide plate 2, for CF CRIMPHANDY 1,5

---

Replacement part - CF CRIMPHANDY/GP1 - 1212514



Waste guide plate 1, for CF CRIMPHANDY 0,5 /0,75 /1,0/1,5

---

#### Battery module

## Electrical crimping tool - CF CRIMPHANDY 1,5 - 1212466

### Accessories

Battery - CF CRIMPHANDY/ACCU - 1212518



Replacement battery for CRIMPHANDY..., Li-ion 7.4 V, 0.68 Ah

---

### Cable end sleeve

Ferrule - Al 1,5-8 BK-S - 1212524



Band ferrules, 1.5 mm<sup>2</sup>, sleeve length 8 mm, with plastic collar, according to DIN 46228-4, color: black, equipped with function end for safe and convenient processing with the Crimphandy, 20 strips with 50 sleeves per strip.

Ferrule - Al 1,5-8 RD-S - 1212781



Taped ferrules, 1.5 mm<sup>2</sup>, sleeve length: 8 mm, with plastic collars, according to DIN 46228-4, special color: red, with function end for safe and convenient processing with the Crimphandy, 20 strips each with 50 sleeves per strip.

---

### Charger

Charger - CF CRIMPHANDY/CHARGER - 1212519




Replacement charger, for 100 V ... 240 V AC mains voltage, short charging time, short-circuit-proof, protected against polarity reversal, operating state indicator

---

### Cover

Cover - CF CRIMPHANDY/COVER - 1212709

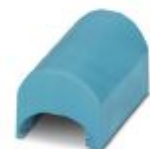

Replacement receptacle tray for CF-CRIMPHANDY

## Electrical crimping tool - CF CRIMPHANDY 1,5 - 1212466

### Accessories

Cutting tool - CF CRIMPHANDY CUTTER - 1212520



Cutting unit, for CF CRIMPHANDY, for stranded copper wires from 0.5 - 1.5 mm<sup>2</sup>, incl. receptacle tray

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1212466