

Screw plug - A-EXSH-M40-68L-N-S - 1411111

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Screw plug, cable gland material: Nickel-plated brass, application: Ex, connecting thread: M40 x 1.5, color: silver



Key Commercial Data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 046356 922265
GTIN	4046356922265

Technical data

Dimensions

Length	24 mm
Length without connecting thread	9 mm
Connecting thread diameter	40 mm
Thread pitch	1.5 mm
Wrench size, union nut	46 mm
Hexagon angular dimension	50.6 mm
Length of the connecting thread	15 mm

Ambient conditions

Degree of protection (IP)	IP66 (using the corresponding A-SEW-...P-W flat gasket)
	IP68 (using the corresponding A-SEW-...P-W flat gasket)
Ambient temperature (operation)	-60 °C ... 130 °C

General

Note	This item must only be used with counter nut 1411246 A-INL-M40-N-S for the Ex e type of protection.
Cable gland material	Nickel-plated brass
Thread type connection side	M40 x 1.5

Screw plug - A-EXSH-M40-68L-N-S - 1411111

Technical data

General

Color	silver
Assembly instructions	Sealed to IP66/IP68 thanks to the use of the A-SEW-40-P-W flat gasket (item 1411286)
Standards/specifications	EN 60079-0, -1, -7
	IEC 60079-0, -1, -7
	EN 61241-0, -1
	IEC 61241-0, -1
Manufacturer	CMP
Manufacturer product number	757DM55
Manufacturer Designation	757 M40 Exd/Exe N.PLTD HEX HD STOP PLUG
Suited for EX-applications	yes

Standards and Regulations

Standards/specifications	EN 60079-0, -1, -7
	IEC 60079-0, -1, -7
	EN 61241-0, -1
	IEC 61241-0, -1
ATEX	Sira 01ATEX1284U
	Sira 02ATEX1003X
	Ex II 2 GD Ex d IIC & Ex e II, Ex IM2 Ex d I, Ex e I
IECEX	IECEX SIR 07.0056X
	Ex d I / Ex e I / Ex d IIC / Ex e II, Ex tD A21 IP6X


Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Screw plug - A-EXSH-M40-68L-N-S - 1411111

Dimensional drawing

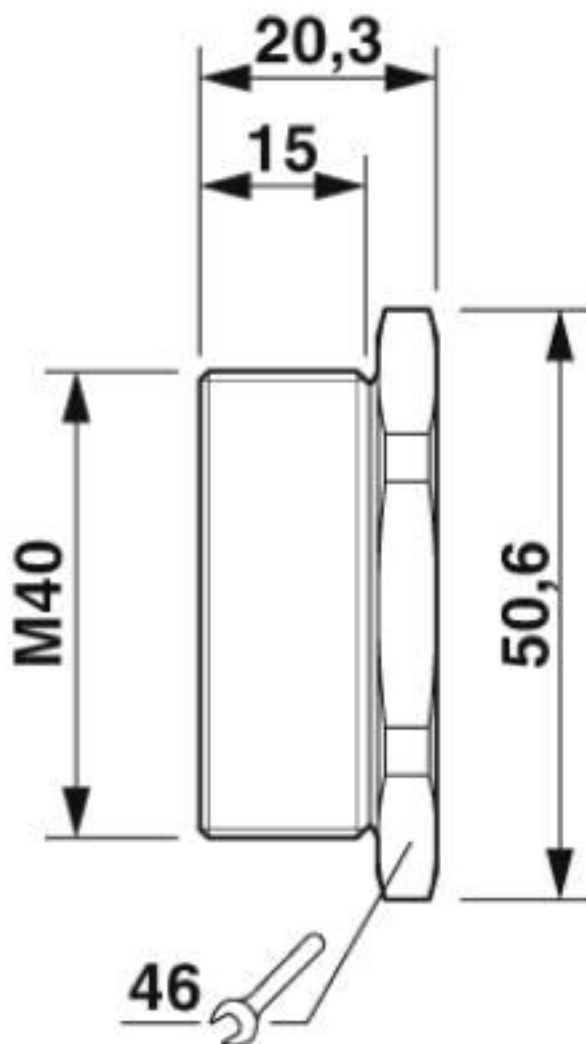

Classifications

eCl@ss

eCl@ss 10.0.1	23111190
eCl@ss 4.0	23111100
eCl@ss 4.1	23111100
eCl@ss 5.0	23111100
eCl@ss 5.1	23111100
eCl@ss 6.0	23111100
eCl@ss 7.0	23111190
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

Screw plug - A-EXSH-M40-68L-N-S - 1411111

Classifications

ETIM

ETIM 4.0	EC000032
ETIM 5.0	EC000032
ETIM 6.0	EC000032
ETIM 7.0	EC000032

UNSPSC

UNSPSC 13.2	31161501
UNSPSC 18.0	31261502
UNSPSC 19.0	31261502
UNSPSC 20.0	31261502
UNSPSC 21.0	31261502

Accessories

Accessories

Flat nut

Counter nut - A-INL-M40-N-S - 1411246



Counter nut, material: Brass, nickel-plated, for threads M40 x 1.5, color: silver

Seal

Flat gasket - A-SEW-40-P-W - 1411286



Flat gasket, material: Nylon, for threads M40, color: white

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1411111