

## Protective covers - HC-B16-HCLWD-PLR-BK - 1414639

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Protective cover B16, with double locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, diameter of retaining cord eyelet: 30 mm



### Key Commercial Data

|              |                                                                                      |
|--------------|--------------------------------------------------------------------------------------|
| Packing unit | 10 pc                                                                                |
| GTIN         |  |
| GTIN         | 4055626131337                                                                        |

### Technical data

#### Dimensions

|                                   |         |
|-----------------------------------|---------|
| Length                            | 93.5 mm |
| Width                             | 43 mm   |
| Height                            | 21.6 mm |
| Diameter of retaining cord eyelet | 30 mm   |

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection (IP)       | IP66              |
| Ambient temperature (operation) | -20 °C ... 100 °C |

#### General

|                                        |                                                                       |
|----------------------------------------|-----------------------------------------------------------------------|
| Note                                   | Protective cover for supporting base element for double locking latch |
| Size                                   | B16                                                                   |
| Material                               | PA                                                                    |
| Seal material                          | NBR                                                                   |
| Flammability rating according to UL 94 | HB                                                                    |
| Color                                  | black                                                                 |
| Seal present                           | yes                                                                   |
| Note                                   | Protective cover for supporting base element for double locking latch |
| Connection                             | Plastic protective cover for short-term protection                    |

# Protective covers - HC-B16-HCLWD-PLR-BK - 1414639

## Technical data

### Standards and Regulations


|                                        |    |
|----------------------------------------|----|
| Flammability rating according to UL 94 | HB |
|----------------------------------------|----|

### Environmental Product Compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Drawings

Dimensional drawing

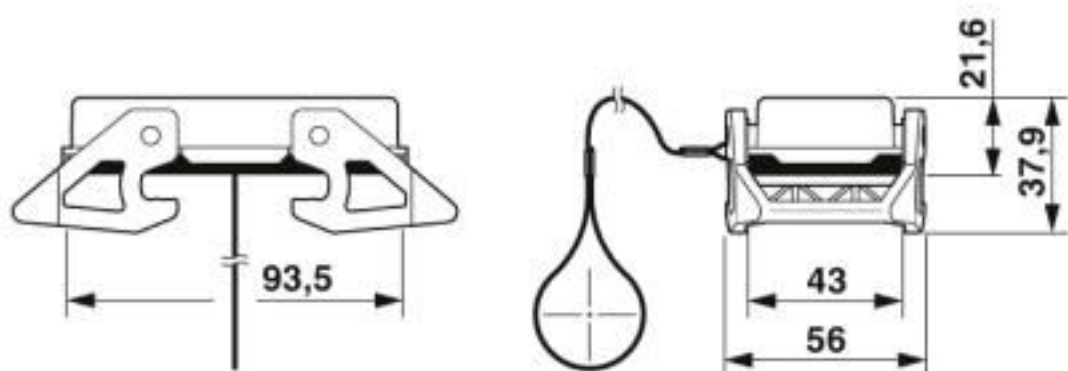

Dimensional drawing

## Classifications

### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27440208 |
| eCl@ss 4.0    | 23110100 |
| eCl@ss 4.1    | 23110100 |
| eCl@ss 5.0    | 23110100 |
| eCl@ss 5.1    | 23110100 |
| eCl@ss 6.0    | 27261200 |
| eCl@ss 7.0    | 27440208 |
| eCl@ss 8.0    | 27440208 |
| eCl@ss 9.0    | 27440208 |

### ETIM

|          |          |
|----------|----------|
| ETIM 5.0 | EC002314 |
| ETIM 6.0 | EC002314 |
| ETIM 7.0 | EC002314 |

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 13.2 | 39121421 |
| UNSPSC 18.0 | 39121421 |

## Protective covers - HC-B16-HCLWD-PLR-BK - 1414639

### Classifications

#### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 19.0 | 39121421 |
| UNSPSC 20.0 | 39121421 |
| UNSPSC 21.0 | 39121421 |

### Approvals

#### Approvals

Approvals

EAC

Ex Approvals

#### Approval details

|     |                                                                                     |                          |
|-----|-------------------------------------------------------------------------------------|--------------------------|
| EAC |  | RU C-<br>DE.AI30.B.01102 |
|-----|-------------------------------------------------------------------------------------|--------------------------|

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1414639