

Cable gland - HC-B-GM5X8,5-M40-PLTBK - 1414645

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid
(<http://phoenixcontact.com/download>)



EVO plastic cable gland with bayonet locking; size M40, for 5 conductors with 8.5 mm cable diameter



Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 030975
GTIN	4055626030975

Technical data

Dimensions

External cable diameter	8.5 mm ... 8.6 mm (Cable 1 ... 5)
-------------------------	-----------------------------------

Ambient conditions

Degree of protection (IP)	IP66 (Cable diameter 8.5 mm $\pm$ 0.1 mm)
Ambient temperature (operation)	-30 °C ... 100 °C

General

Type of the screw connection	M40
No. of conductors	5
Material	PA
Cable gland material	PA
Material, pressure screw	PBT
Shielded	no
Color	black


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Cable gland - HC-B-GM5X8,5-M40-PLTBK - 1414645

Drawings

Dimensional drawing

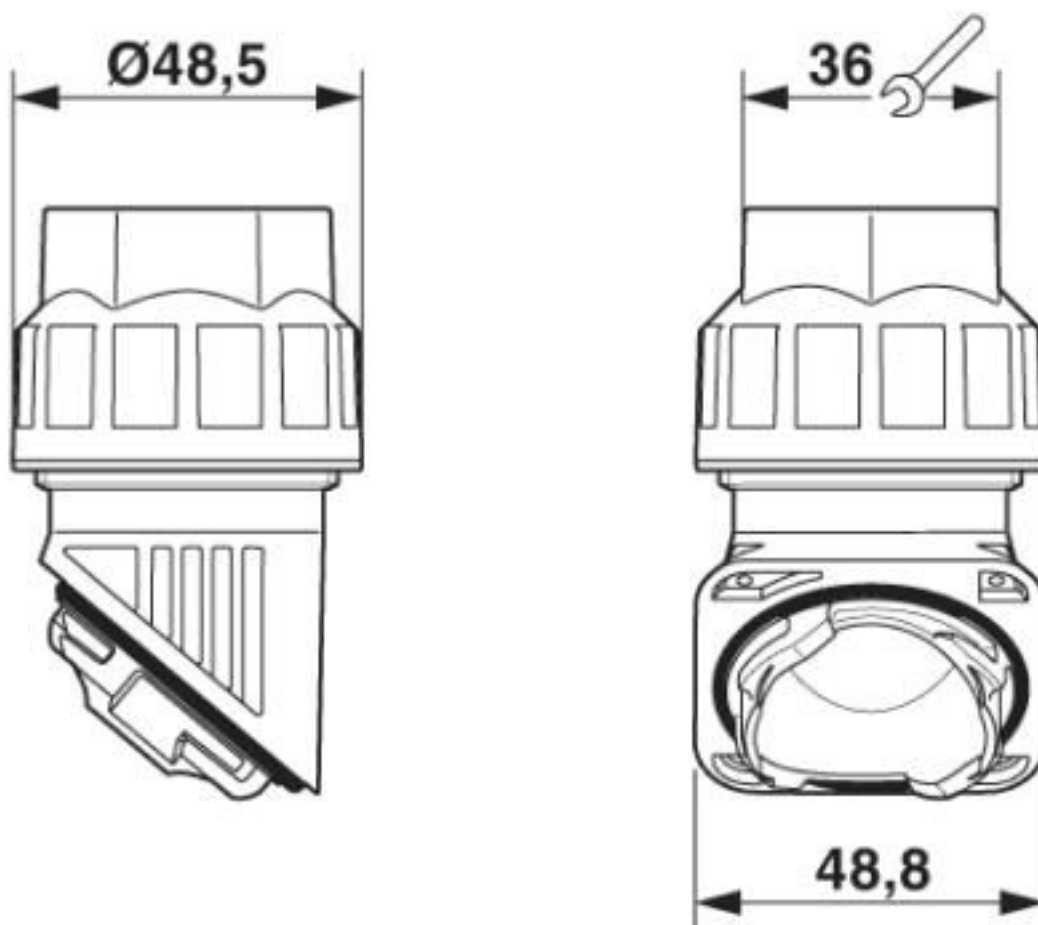

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	27144432
eCl@ss 4.0	27140800
eCl@ss 4.1	27140800
eCl@ss 5.0	27149100
eCl@ss 5.1	27143400
eCl@ss 6.0	27149100
eCl@ss 7.0	27149109
eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

Cable gland - HC-B-GM5X8,5-M40-PLTBK - 1414645

Classifications

ETIM

ETIM 5.0	EC000441
ETIM 6.0	EC000441
ETIM 7.0	EC000441

UNSPSC

UNSPSC 13.2	39121311
UNSPSC 18.0	39121311
UNSPSC 19.0	39121311
UNSPSC 20.0	39121311
UNSPSC 21.0	39121311

Approvals

Approvals

Approvals

EAC-RoHS / EAC

Ex Approvals

Approval details

EAC-RoHS	EAC	RU D- DE.HB35.B.00387
----------	------------	--------------------------

EAC	EAC	RU C- DE.AI30.B.01102
-----	------------	--------------------------

Accessories

Accessories

Sealing plugs

Closing cap - SEALING PLUG 9X16 RD - 1400259



Closing cap, material: PA, color: red

Cable gland - HC-B-GM5X8,5-M40-PLTBK - 1414645

Accessories

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1414645](#)