

## Profile gasket - HC-D15-SP-RBK - 1414671

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Replacement profile gasket, for HC-EVO-D15....BK housing



### Key Commercial Data

|              |                                                                                                         |
|--------------|---------------------------------------------------------------------------------------------------------|
| Packing unit | 10 pc                                                                                                   |
| GTIN         | <br>4 055626 031224 |
| GTIN         | 4055626031224                                                                                           |

### Technical data

#### Dimensions

|        |         |
|--------|---------|
| Length | 63.5 mm |
| Width  | 30 mm   |
| Height | 4 mm    |

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|

#### General


|                       |                                                                  |
|-----------------------|------------------------------------------------------------------|
| Size                  | D15                                                              |
| Material              | NBR                                                              |
| Seal material         | NBR                                                              |
| Color                 | black                                                            |
| Assembly instructions | The replacement seal should be bonded with Loctite 454 adhesive. |
| Connection            | For HC-EVO-D15....BK housing                                     |

### Environmental Product Compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Profile gasket - HC-D15-SP-RBK - 1414671

### Drawings

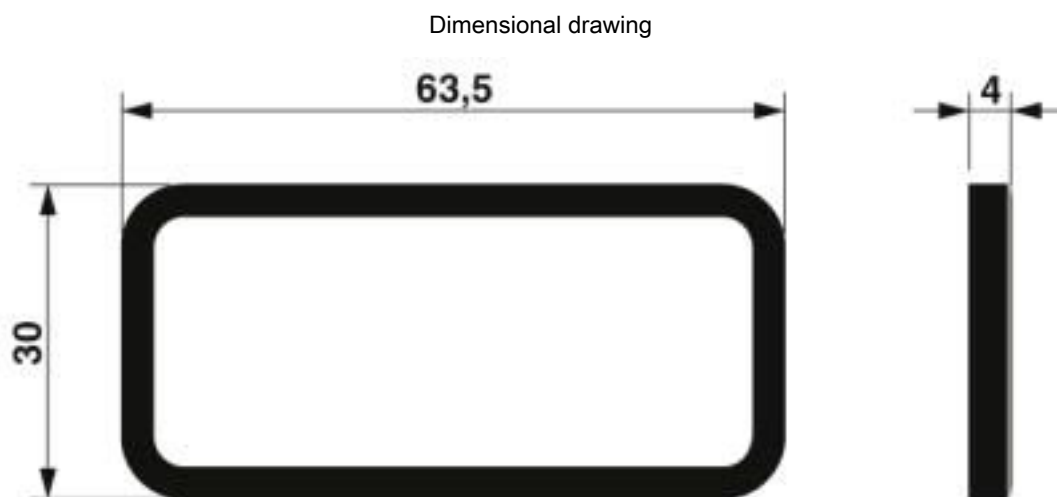

Dimensional drawing

### Classifications

eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 23071590 |
| eCl@ss 4.0    | 23110100 |
| eCl@ss 4.1    | 23110100 |
| eCl@ss 5.0    | 23110100 |
| eCl@ss 5.1    | 23110100 |
| eCl@ss 6.0    | 23071500 |
| eCl@ss 7.0    | 23071590 |
| eCl@ss 8.0    | 23071590 |
| eCl@ss 9.0    | 23071590 |

ETIM

|          |          |
|----------|----------|
| ETIM 5.0 | EC001181 |
| ETIM 6.0 | EC001181 |
| ETIM 7.0 | EC001181 |

UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 13.2 | 31401601 |
| UNSPSC 18.0 | 31401601 |
| UNSPSC 19.0 | 31401601 |
| UNSPSC 20.0 | 31401601 |
| UNSPSC 21.0 | 31401601 |

### Approvals

Approvals

## Profile gasket - HC-D15-SP-RBK - 1414671

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

EAC



RU C-  
DE.AI30.B.01102

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1414671