


Interface module - FLKM14/FLK14/ZFKDS/DI8/SO199 - 2310840

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

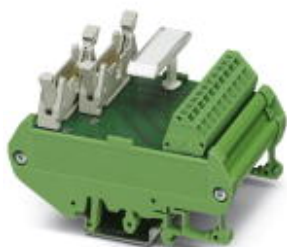

VARIOFACE interface module for redundant connection of 2x8 input channels (SIMATIC® S7 / S5) via 2xFLK14 on spring-cage terminal blocks

RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	25 pc
GTIN	 4 046356 128520
GTIN	4046356128520

Technical data

Dimensions

Width	57 mm
Height	90 mm
Depth	67 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

General

Max. perm. operating voltage	25 V AC (50 V DC)
Max. perm. current (per branch)	1 A
Max. permissible current (separate power supply)	3 A (via terminal blocs 01 and 10)
Status display	No
Mounting position	any
Assembly instructions	In rows with zero spacing
Degree of protection	IP00

Connection data for connection 1

Interface module - FLKM14/FLK14/ZFKDS/DI8/SO199 - 2310840

Technical data

Connection data for connection 1

Connection name	Field level
Connection method	Spring-cage connection
Stripping length	7 mm
Conductor cross section solid	0.2 mm² ... 2.5 mm²
Conductor cross section flexible	0.2 mm² ... 1.5 mm²
Conductor cross section AWG	24 ... 14

Connection data for connection 2

Connection name	Controller level
Connection method	IDC/FLK pin strip
Number of connections	2
Number of positions	14
Pitch	2.54 mm

Standards and Regulations

Designation	Air clearances and creepage distances
Standards/regulations	DIN EN 50178: 1998-04
Rated insulation voltage	50 V
Rated surge voltage	0.5 kV (1.2/50 µs)
Insulation	Functional insulation
Degree of pollution	2
Overvoltage category	II

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

Interface module - FLKM14/FLK14/ZFKDS/DI8/SO199 - 2310840

Approvals

EAC



RU C-
DE.A*30.B.01742

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[2310840](#)