


## Marker for terminal blocks - UM1-TM (8X12) OG - 0833061

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Markers for marking terminal blocks from Weidmüller, Conta Clip, and Klemmsan, 14-section, unmarked, can be marked with THERMOMARK CARD and BLUEMARK, color: orange

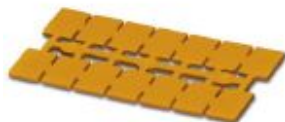

RoHS

### Key Commercial Data

|                        |                                                                                                         |
|------------------------|---------------------------------------------------------------------------------------------------------|
| Packing unit           | 10 pc                                                                                                   |
| Minimum order quantity | 10 pc                                                                                                   |
| GTIN                   | <br>4 046356 985093 |
| GTIN                   | 4046356985093                                                                                           |

### Technical data

#### Dimensions

|            |       |
|------------|-------|
| Length (b) | 12 mm |
| Width (a)  | 8 mm  |

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 120 °C |
|---------------------------------|-------------------|

#### General

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Color                                  | orange                                   |
| Type                                   | high                                     |
| Components                             | free from silicone, halogen, and cadmium |
| Flammability rating according to UL 94 | V2                                       |
| Material                               | PC                                       |
| RoHS compliant                         | Yes                                      |
| Wipe resistance                        | DIN EN 61010-1 (VDE 0411-1)              |
| Number of individual labels            | 14                                       |
| Number of individual labels per row    | 7                                        |
| Number of marker strips                | 2                                        |
| Printability                           | Thermal transfer                         |

## Marker for terminal blocks - UM1-TM (8X12) OG - 0833061

### Technical data

#### General

|                                                                     |                                  |
|---------------------------------------------------------------------|----------------------------------|
| Device                                                              | 5146464 THERMOMARK CARD          |
| Ink ribbon                                                          | 0801371 THERMOMARK-RIBBON 110-TC |
| Test for substances that would hinder coating with paint or varnish | VW PV 3.10.7:2005-02             |
| Result                                                              | Test passed                      |
| Test specification weathering-resistance                            | Following ISO 4892-2:2013-03     |
| Test duration                                                       | 96 h                             |
| Result of weather resistance test                                   | Test passed                      |
| Salt spray test specification                                       | DIN EN 60068-2-11:2000-02        |
| Test duration                                                       | 96 h                             |
| Salt spray testing result                                           | Test passed                      |
| Alternating condensation climate with SO2 test specification        | DIN 50018:2013-05                |
| Climate level                                                       | AHT 1.0 S                        |
| Cycles                                                              | 2                                |
| Condensation test result                                            | Test passed                      |
| Wipe resistance of test specification inscriptions                  | IEC 61010-1:2010-06              |
| Result of wipe resistance test                                      | Test passed                      |
| Marking mounting type                                               | clip on                          |

#### Standards and Regulations

|                                        |                             |
|----------------------------------------|-----------------------------|
| Wipe resistance                        | DIN EN 61010-1 (VDE 0411-1) |
| Flammability rating according to UL 94 | V2                          |

### Classifications

#### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27141137 |
| eCl@ss 5.0    | 27141100 |
| eCl@ss 5.1    | 27141100 |
| eCl@ss 6.0    | 27141100 |
| eCl@ss 7.0    | 27141137 |
| eCl@ss 8.0    | 27141137 |
| eCl@ss 9.0    | 27141137 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 5.0 | EC000761 |
| ETIM 6.0 | EC000761 |
| ETIM 7.0 | EC000761 |

#### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 13.2 | 39131505 |
| UNSPSC 18.0 | 39131505 |
| UNSPSC 19.0 | 39131505 |

## Marker for terminal blocks - UM1-TM (8X12) OG - 0833061

### Classifications

#### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 20.0 | 39131505 |
| UNSPSC 21.0 | 39131505 |

### Accessories

#### Accessories

#### Magazine

Magazine - TMP-UM-MAG1 - 0831200



Magazine for the THERMOMARK CARD printer, for accommodating UM material (UM1-TM and UM5-TM)

---

Magazine - BLUEMARK MAG UM-TM - 0803335



Magazine for the BLUEMARK printer, for accommodating UM materials

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[0833061](#)