

# Marking foil for zack marker strip - TML (101X9,5)R P12 TR CUS - 0852157

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Marking foil for zack marker strip, Roll, can be ordered: by line, transparent, labeled according to customer specifications, can be labeled with: THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: adhesive, for terminal block width: 12 mm, lettering field size: 101 mm x 9.5 mm

## Your advantages

- ✓ The TML labeling range offers the option of subsequent labeling of zack marker strip and flat zack marker strip materials using a marking foil
- ✓ Quick and inexpensive marking with THERMOMARK ... roll printers from PHOENIX CONTACT
- ✓ Labeling service: Phoenix Contact can custom-label all TML markers according to your requirements
- ✓ The markers that are supplied in roll format can be labeled quickly and cost-effectively using THERMOMARK printers



## Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356355322

## Technical data

### Dimensions

Length (b)	101 mm
Width (a)	9.5 mm

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 150 °C
---------------------------------	-------------------

### General

Color	transparent
Type	flat
Components	Silicone-free
Material	Polyester
Wipe resistance	DIN EN 61010-1 (VDE 0411-1)

# Marking foil for zack marker strip - TML (101X9,5)R P12 TR CUS - 0852157

## Technical data

### General


Marking mounting type	adhesive
-----------------------	----------

### Standards and Regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

## Drawings

Schematic diagram

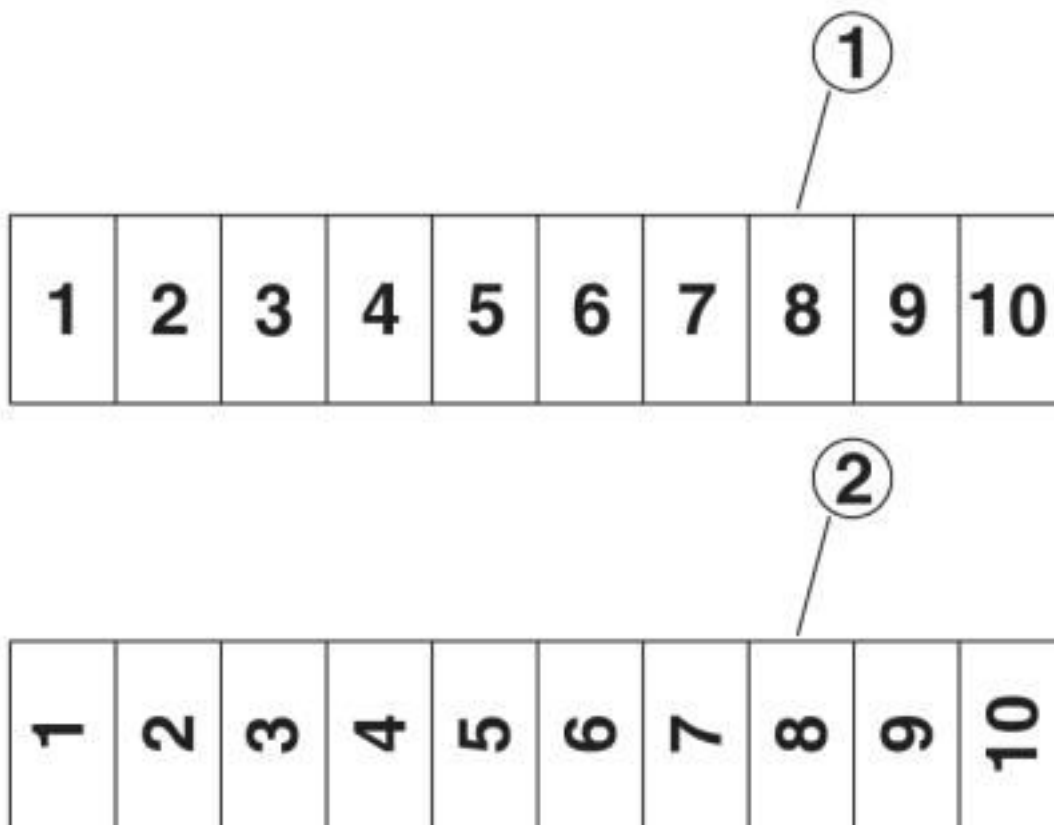

- ① Horizontal
- ② Vertical

## Classifications

eCl@ss

eCl@ss 10.0.1	27141137
eCl@ss 4.0	24190200
eCl@ss 4.1	24190200
eCl@ss 5.0	27141100

# Marking foil for zack marker strip - TML (101X9,5)R P12 TR CUS - 0852157

## Classifications

### eCl@ss

eCl@ss 5.1	27141100
eCl@ss 6.0	27141100
eCl@ss 7.0	27141137
eCl@ss 8.0	27141137
eCl@ss 9.0	27141137

### ETIM

ETIM 3.0	EC000761
ETIM 4.0	EC000761
ETIM 5.0	EC000761
ETIM 6.0	EC000761
ETIM 7.0	EC000761

### UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39131505
UNSPSC 18.0	39131505
UNSPSC 19.0	39131505
UNSPSC 20.0	39131505
UNSPSC 21.0	39131505

## Accessories

### Accessories

#### Ink ribbon

Ink ribbon - THERMOMARK-RIBBON 110 - 5145384



Ink ribbon, for roll printers for printing the product groups TML..., WML..., WML HF..., WML-FLAG..., EML..., EML-ESD..., EML-RM..., EML-HA..., EMLS..., EMLC..., EMLP... and PMM..., width: 110 mm, color: black

## Marking foil for zack marker strip - TML (101X9,5)R P12 TR CUS - 0852157

### Accessories

Ink ribbon - THERMOMARK-RIBBON 110/50 - 0800687



Ink ribbon, for roll printers for printing the product groups TML..., WML..., WML HF..., WML-FLAG..., EML..., EML-ESD..., EML-RM..., EML-HA..., EMLS..., EMLC..., EMLP... and PMM..., width: 110 mm, color: black

---

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[0852157](#)