

Network cable - NBC-R4BQ/1,5-94B/R4BQRB - 1424824

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Network cable, degree of protection: IP20, cable length: 1.5 m, number of positions: 8, 1 Gbps, CAT5 (IEC 11801:2002), material: Zinc die-cast, connection method: IDC fast connection

Your advantages

✓ 360° shielding



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	50 pc
GTIN	 4 055626 384726
GTIN	4055626384726

Technical data


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings


Network cable - NBC-R4BQ/1,5-94B/R4BQRB - 1424824

Dimensional drawing

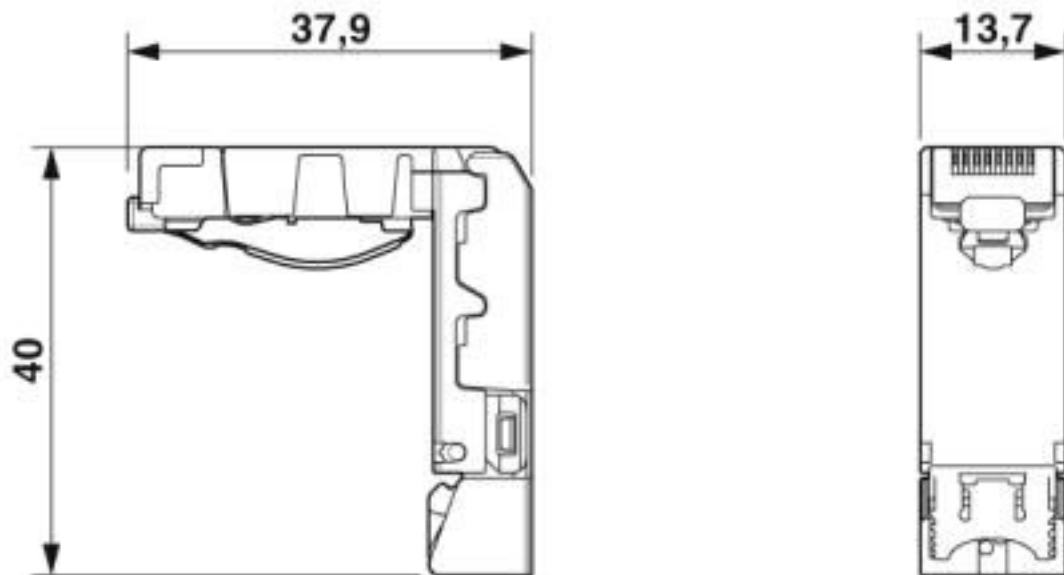

RJ45 connector, IP20, angled

Dimensional drawing

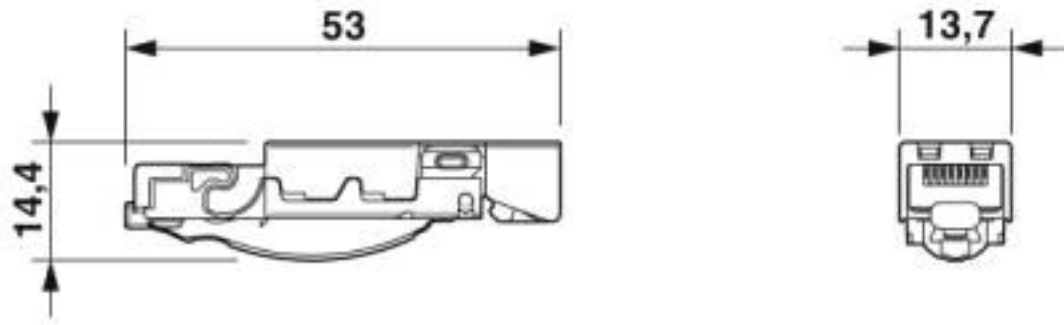

RJ45 connector, IP20

Network cable - NBC-R4BQ/1,5-94B/R4BQRB - 1424824

Cable cross section



Ethernet flexible CAT5, 4-pair [94B]

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1424824