

## Network cable - NBC-M12FR/2,0-971/R4AQ VR - 1425619

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Assembled VARAN cable, shielded, stranded, black, angled M12 socket, SPEEDCON, 6-pos. to RJ45 plug/ IP20, QUICKON, length: 2 m



### Key Commercial Data

|                        |                                                                                                         |
|------------------------|---------------------------------------------------------------------------------------------------------|
| Packing unit           | 1 pc                                                                                                    |
| Minimum order quantity | 50 pc                                                                                                   |
| GTIN                   | <br>4 055626 409023 |
| GTIN                   | 4055626409023                                                                                           |

### Technical data


#### Environmental Product Compliance

|            |                |
|------------|----------------|
| REACH SVHC | Lead 7439-92-1 |
|------------|----------------|

### Drawings


## Network cable - NBC-M12FR/2,0-971/R4AQ VR - 1425619

Schematic diagram

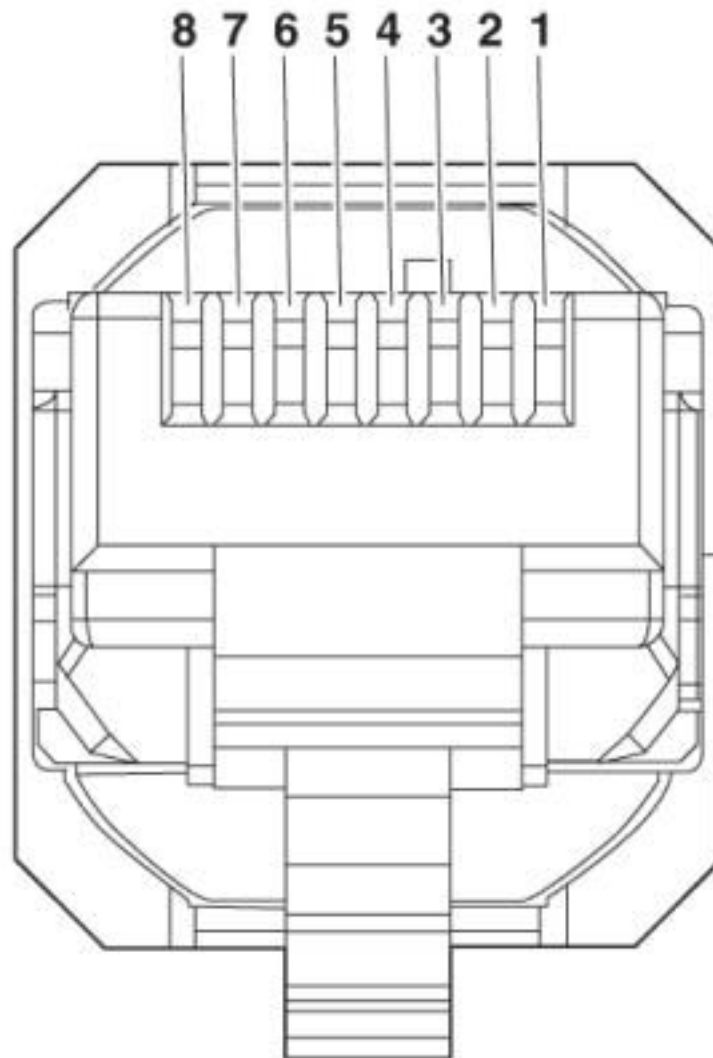

## Network cable - NBC-M12FR/2,0-971/R4AQ VR - 1425619


Schematic diagram

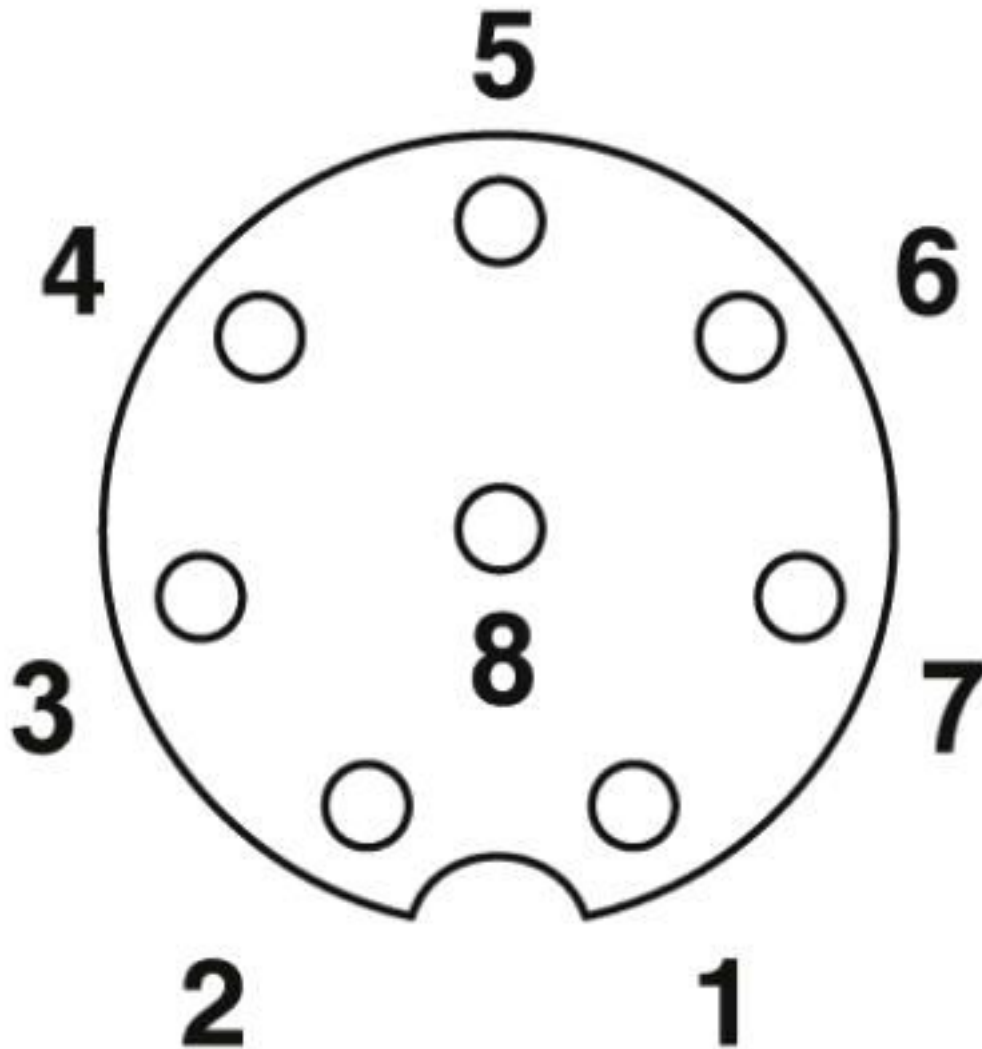

Pin assignment M12 socket, 8-pos., A-coded, view female side

## Network cable - NBC-M12FR/2,0-971/R4AQ VR - 1425619


Dimensional drawing

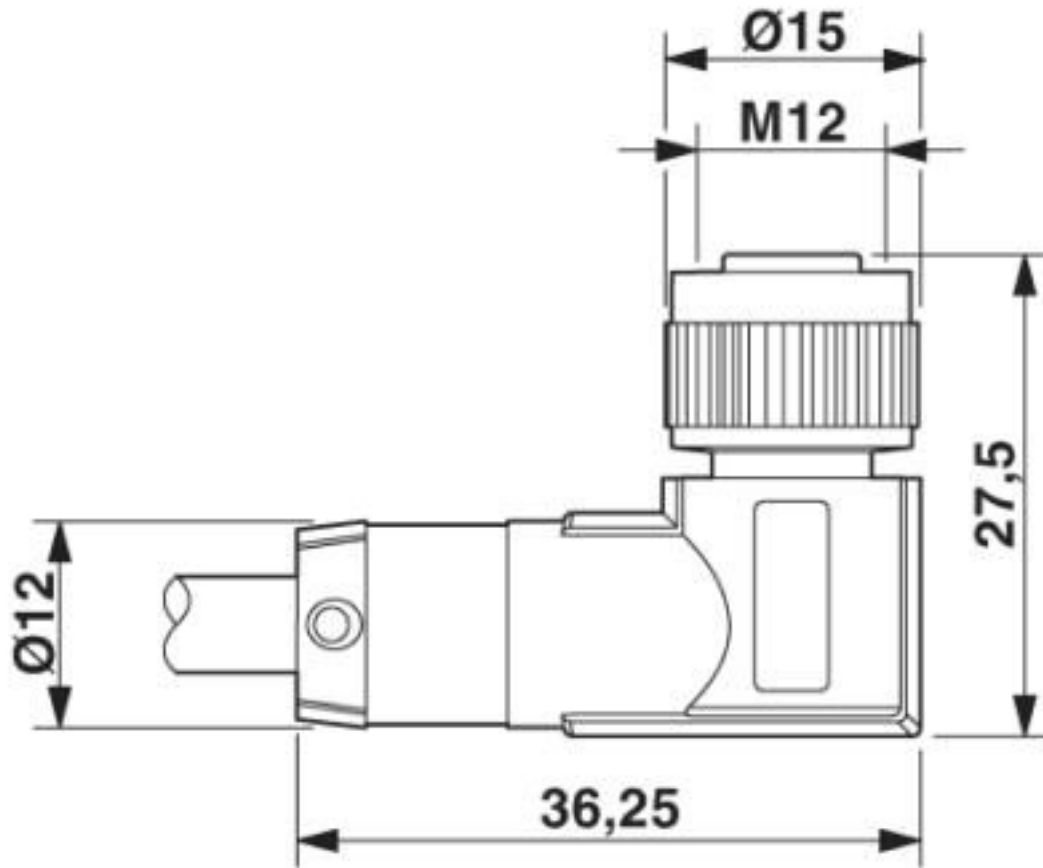

M12 x 1 socket, angled, shielded

## Network cable - NBC-M12FR/2,0-971/R4AQ VR - 1425619

Circuit diagram

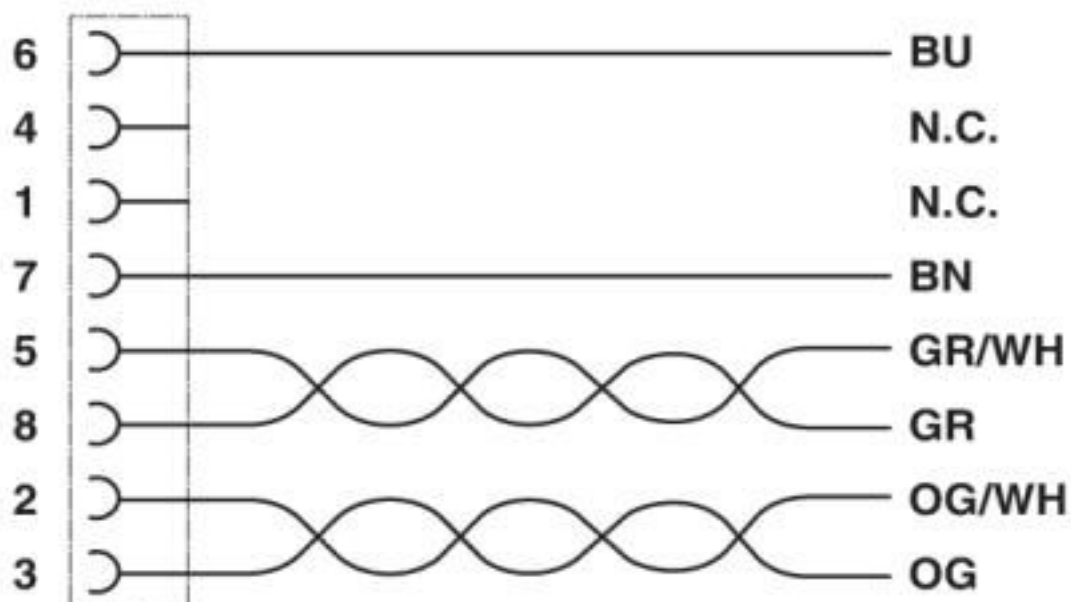

Contact assignment of the M12 socket

### Classifications

eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27440102 |
| eCl@ss 5.1    | 27143423 |
| eCl@ss 6.0    | 27279200 |
| eCl@ss 7.0    | 27440103 |
| eCl@ss 8.0    | 27440103 |
| eCl@ss 9.0    | 27440102 |

ETIM

|          |          |
|----------|----------|
| ETIM 5.0 | EC002061 |
| ETIM 6.0 | EC002061 |

### Approvals

Approvals

Approvals

EAC

Ex Approvals

## Network cable - NBC-M12FR/2,0-971/R4AQ VR - 1425619

### Approvals

#### Approval details

|     |                                                                                   |          |
|-----|-----------------------------------------------------------------------------------|----------|
| EAC |  | 19060508 |
|-----|-----------------------------------------------------------------------------------|----------|

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Phoenix Contact:

1425619