

## Docking frames - HC-B 10-ANDOCK - 1586125

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Docking frame for racks, for contact inserts of B10 type, with four M5 flat headed screws, rack balance x/y axis  $\pm 1.5$  mm



### Key Commercial Data

|                        |                                                                                                         |
|------------------------|---------------------------------------------------------------------------------------------------------|
| Packing unit           | 2 pc                                                                                                    |
| Minimum order quantity | 2 pc                                                                                                    |
| GTIN                   | <br>4 046356 345736 |
| GTIN                   | 4046356345736                                                                                           |

### Technical data

#### Dimensions

|        |       |
|--------|-------|
| Height | 99 mm |
| Width  | 55 mm |

#### General

|                       |                                                                               |
|-----------------------|-------------------------------------------------------------------------------|
| Material              | Stainless steel                                                               |
| Type                  | B10                                                                           |
| Assembly instructions | Due to the floating docking frame, a metal attachment panel must be grounded. |
| Connection            | For contact inserts from series B10, DD42, BB18, K, M                         |


### Environmental Product Compliance

|            |                                                                                                     |
|------------|-----------------------------------------------------------------------------------------------------|
| China RoHS | Environmentally Friendly Use Period = 50 years                                                      |
|            | For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration" |

### Drawings

## Docking frames - HC-B 10-ANDOCK - 1586125


Dimensional drawing

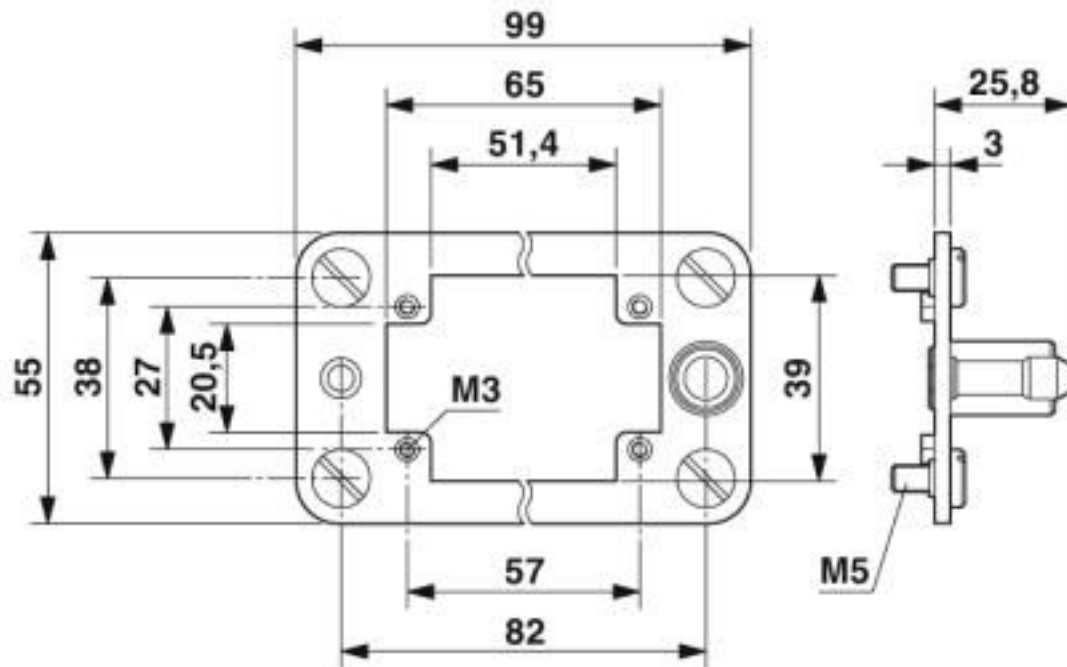

Dimensional drawing


## Docking frames - HC-B 10-ANDOCK - 1586125

Dimensional drawing

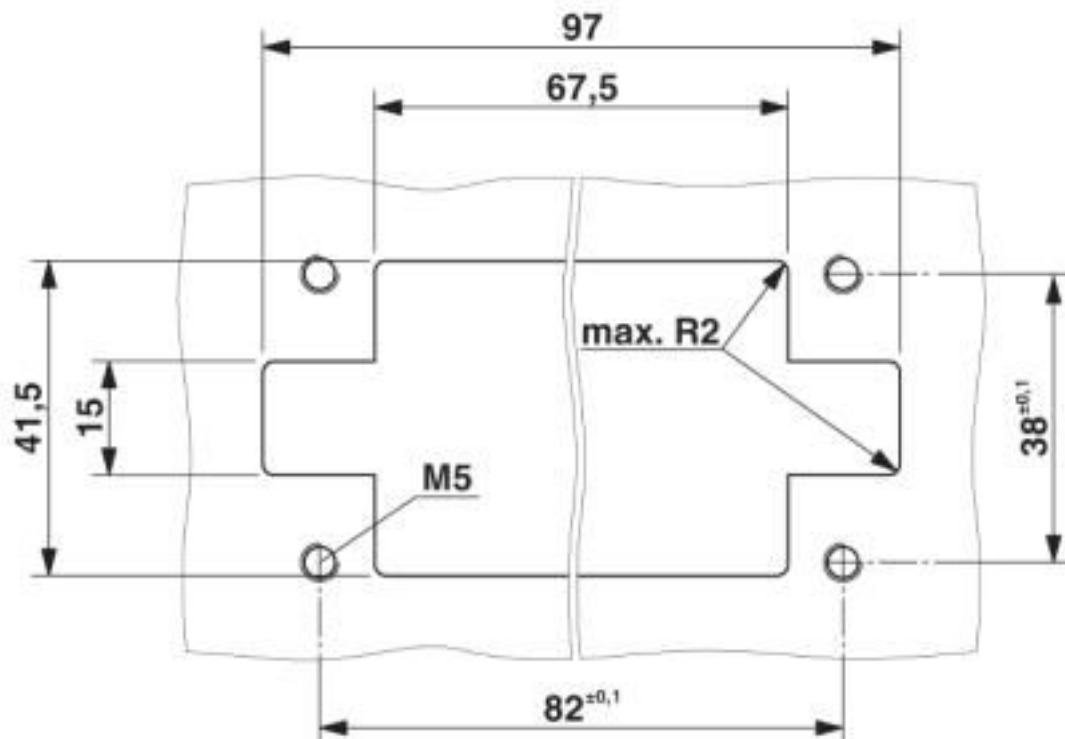

Mounting cutout

Dimensional drawing

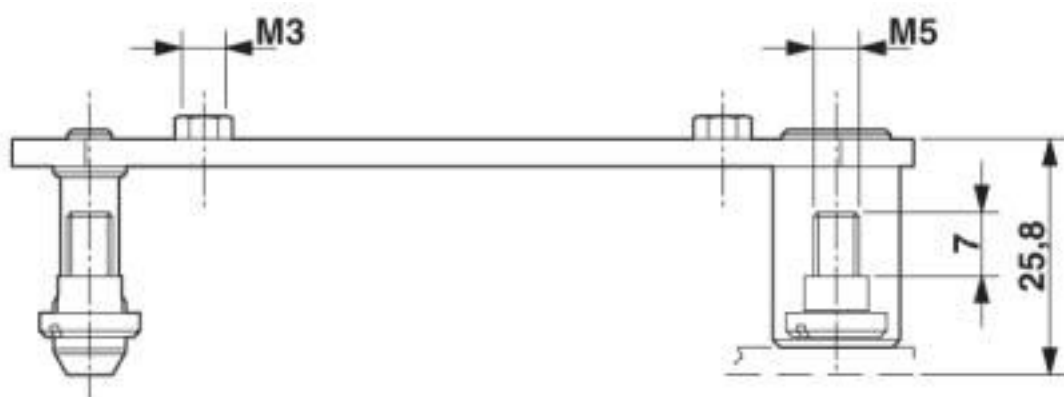

max. dimensions of both the docking frames (in case of standard contacts 25.8 mm; in case of fiber optics contacts 27 mm; in case of pneumatic contacts 26.5 mm)

### Classifications

eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27440206 |
| eCl@ss 4.0    | 27260700 |

## Docking frames - HC-B 10-ANDOCK - 1586125

### Classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.1 | 27260700 |
| eCl@ss 5.0 | 27189200 |
| eCl@ss 5.1 | 27189200 |
| eCl@ss 6.0 | 27261200 |
| eCl@ss 7.0 | 27440210 |
| eCl@ss 8.0 | 27440210 |
| eCl@ss 9.0 | 27440206 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 3.0 | EC002310 |
| ETIM 4.0 | EC002310 |
| ETIM 5.0 | EC002310 |
| ETIM 6.0 | EC002312 |
| ETIM 7.0 | EC002312 |

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211817 |
| UNSPSC 7.0901 | 39121416 |
| UNSPSC 11     | 43172601 |
| UNSPSC 12.01  | 39121522 |
| UNSPSC 13.2   | 39121421 |
| UNSPSC 18.0   | 31261501 |
| UNSPSC 19.0   | 31261501 |
| UNSPSC 20.0   | 31261501 |
| UNSPSC 21.0   | 31261501 |

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1586125](#)