

Adapter plate - VS-ADP16-RJ45/RJ45 - 1652156

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid
(<http://phoenixcontact.com/download>)



Adapter plate, size B16, reinforced, including the RJ45/IP67 panel mounting frame for modular socket inserts with protective cover and without contact insert, and the RJ45/IP67 panel mounting frame for modular socket inserts with protective cover and without contact insert



Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4017918910167

Technical data

Dimensions

Width	30.3 mm
Height	52 mm
Length	123 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 80 °C
---------------------------------	------------------

General data

Alternative short product description	Adapter plate for connector
Housing material	PA
Degree of protection	IP54

Standards and Regulations

Flammability rating according to UL 94	HB
--	----


Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Adapter plate - VS-ADP16-RJ45/RJ45 - 1652156


Drawings

Dimensional drawing

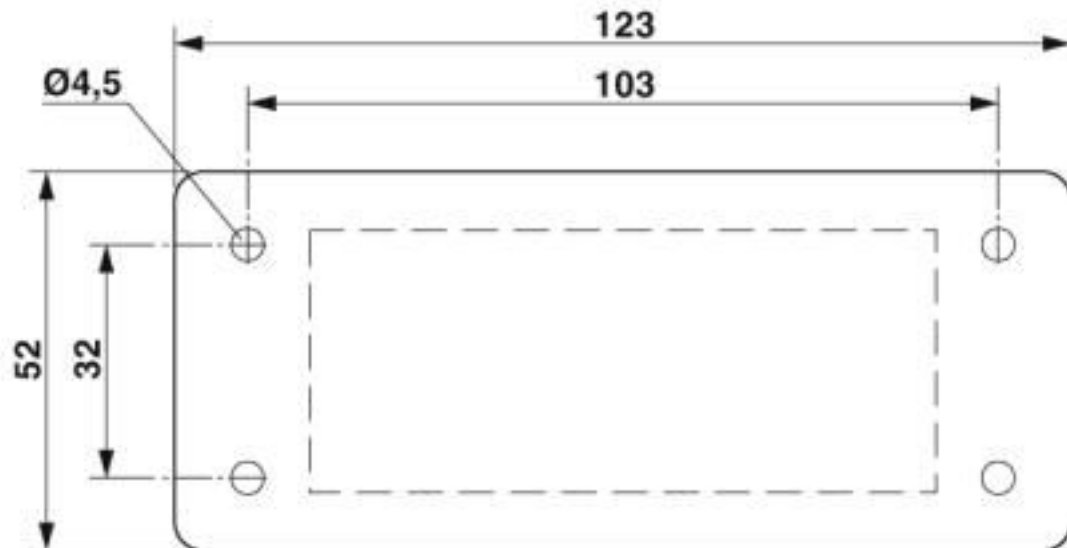

Adapter plate

Dimensional drawing

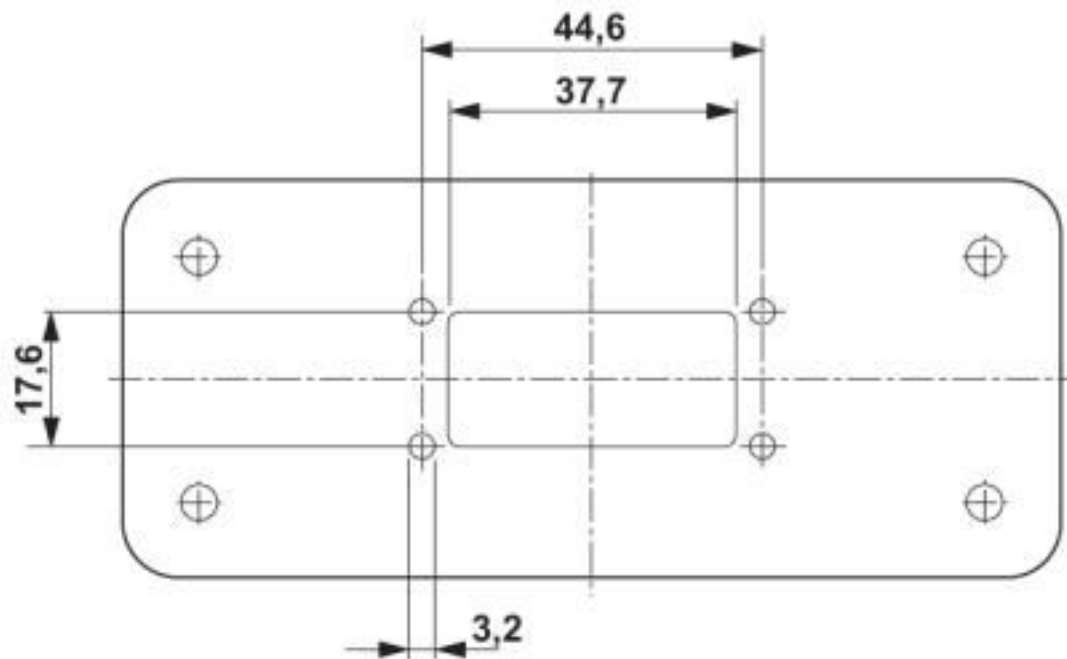

Mounting cutout

Adapter plate - VS-ADP16-RJ45/RJ45 - 1652156

Classifications

eCl@ss

eCl@ss 10.0.1	27440201
eCl@ss 4.0	27140800
eCl@ss 4.1	27140800
eCl@ss 5.0	27189200
eCl@ss 5.1	27189200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440201
eCl@ss 8.0	27440201
eCl@ss 9.0	27440201

ETIM

ETIM 2.0	EC000007
ETIM 3.0	EC000007
ETIM 4.0	EC000007
ETIM 5.0	EC002309
ETIM 6.0	EC002309
ETIM 7.0	EC002309

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

Adapter plate - VS-ADP16-RJ45/RJ45 - 1652156

Approvals

EAC		B.01687
-----	---	---------

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1652156](#)