

Cover plate - HC-B 24-APV-GY - 1661037

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON cover plate, for wall cutouts of type B24, 7 mm thick, gray

RoHS

Key Commercial Data

Packing unit	10 pc
GTIN	 4 017918 022433
GTIN	4017918022433

Technical data

Dimensions

Length	150 mm
Height	7 mm
Hole diameter	4.5 mm
Width	52 mm
Drill hole distance, horizontal	130 mm
Drill hole distance, vertical	32 mm

General

Note	For wall cutouts of type B24
Material	PA
Flammability rating according to UL 94	HB
Color	gray
Type	B24

Standards and Regulations

Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
------------	--

Cover plate - HC-B 24-APV-GY - 1661037


Technical data

Environmental Product Compliance

	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"
--	---

Drawings

Dimensional drawing

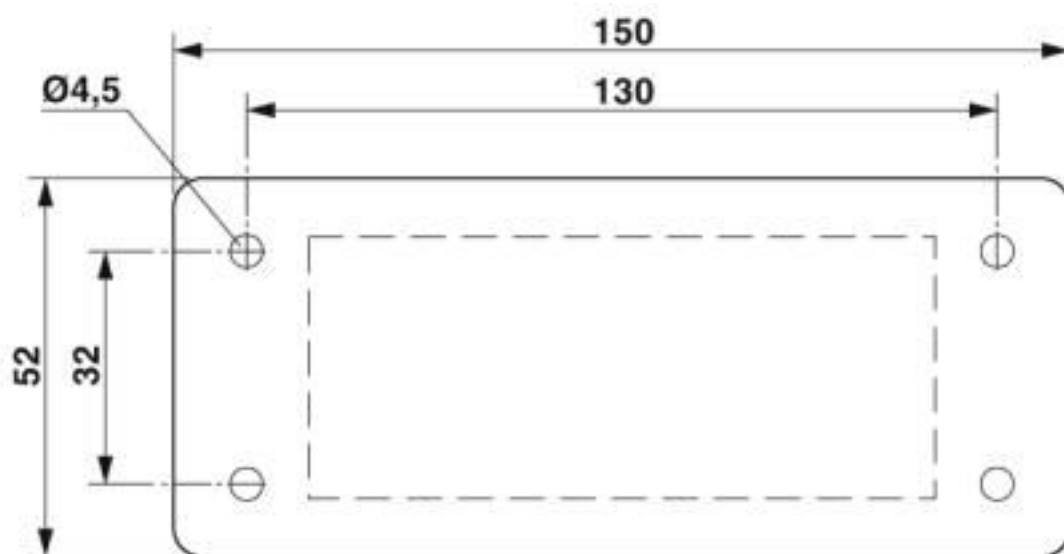

Processing area 2 mm thick

Classifications

eCl@ss

eCl@ss 10.0.1	27440201
eCl@ss 4.0	27140800
eCl@ss 4.1	27140800
eCl@ss 5.0	27143400
eCl@ss 5.1	27143400
eCl@ss 6.0	27261200
eCl@ss 7.0	27440201
eCl@ss 8.0	27440201
eCl@ss 9.0	27440201

ETIM

ETIM 3.0	EC002309
ETIM 4.0	EC000886
ETIM 5.0	EC002309
ETIM 6.0	EC002309

Cover plate - HC-B 24-APV-GY - 1661037

Classifications

ETIM

ETIM 7.0	EC002309
----------	----------

UNSPSC

UNSPSC 6.01	30211817
UNSPSC 7.0901	39121416
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1661037](#)