

## Protective covers - HC-B 24-SD-MQ/FS - 1678347

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Protective cover B24, with double locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, with lanyard, diameter of retaining cord eyelet: 30 mm



### Key Commercial Data

|              |                                                                                                         |
|--------------|---------------------------------------------------------------------------------------------------------|
| Packing unit | 10 pc                                                                                                   |
| GTIN         | <br>4 017918 151881 |
| GTIN         | 4017918151881                                                                                           |

### Technical data

#### Dimensions

|                                   |         |
|-----------------------------------|---------|
| Length                            | 120 mm  |
| Width                             | 43 mm   |
| Height                            | 21.6 mm |
| Diameter of retaining cord eyelet | 30 mm   |

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection (IP)       | IP66              |
| Ambient temperature (operation) | -20 °C ... 100 °C |

#### General

|                                        |                                                    |
|----------------------------------------|----------------------------------------------------|
| Size                                   | B24                                                |
| Type                                   | for sleeve housing without double locking latch    |
| Material                               | PA                                                 |
| Seal material                          | NBR                                                |
| Locking latch material                 | High-grade steel, handle: PA-GF                    |
| Flammability rating according to UL 94 | HB                                                 |
| Color                                  | gray                                               |
| Seal present                           | yes                                                |
| Connection                             | Plastic protective cover for short-term protection |

## Protective covers - HC-B 24-SD-MQ/FS - 1678347

### Technical data

#### Standards and Regulations


|                                        |    |
|----------------------------------------|----|
| Flammability rating according to UL 94 | HB |
|----------------------------------------|----|

#### Environmental Product Compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

### Drawings

Dimensional drawing

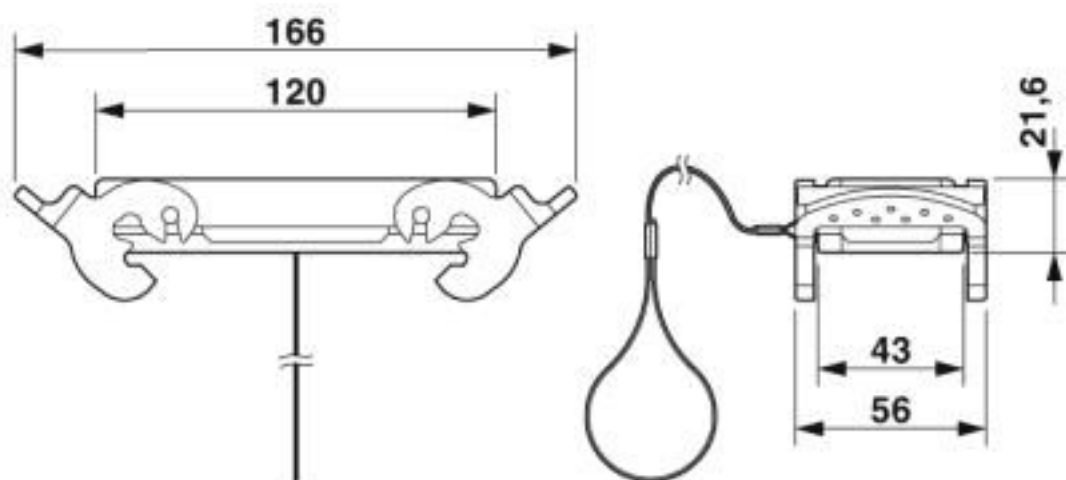

Dimensional drawing

### Classifications

#### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27440208 |
| eCl@ss 4.0    | 27140800 |
| eCl@ss 4.1    | 27140800 |
| eCl@ss 5.0    | 27143400 |
| eCl@ss 5.1    | 27143400 |
| eCl@ss 6.0    | 27261200 |
| eCl@ss 7.0    | 27440208 |
| eCl@ss 8.0    | 27440208 |
| eCl@ss 9.0    | 27440208 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 2.0 | EC000437 |
| ETIM 3.0 | EC000437 |
| ETIM 4.0 | EC000437 |

## Protective covers - HC-B 24-SD-MQ/FS - 1678347

### Classifications

#### ETIM

|          |          |
|----------|----------|
| ETIM 5.0 | EC002314 |
| ETIM 6.0 | EC002314 |
| ETIM 7.0 | EC002314 |

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30212113 |
| UNSPSC 7.0901 | 39121712 |
| UNSPSC 11     | 39121712 |
| UNSPSC 12.01  | 39121712 |
| UNSPSC 13.2   | 39121421 |
| UNSPSC 18.0   | 39121421 |
| UNSPSC 19.0   | 39121421 |
| UNSPSC 20.0   | 39121421 |
| UNSPSC 21.0   | 39121421 |

### Approvals

#### Approvals

#### Approvals

#### EAC

#### Ex Approvals

### Approval details

|     |                                                                                     |                          |
|-----|-------------------------------------------------------------------------------------|--------------------------|
| EAC |  | RU C-<br>DE.AI30.B.01102 |
|-----|-------------------------------------------------------------------------------------|--------------------------|

Phoenix Contact 2020 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1678347](#)