

## Cable housing - KGS-PC 4/ 9-F - 1837382

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable housing, pitch: 0 mm, number of positions: 9, dimension a: 70.98 mm, color: green

The figure shows an 10-position version

RoHS

### Key Commercial Data

|              |                                                                                                         |
|--------------|---------------------------------------------------------------------------------------------------------|
| Packing unit | 10 pc                                                                                                   |
| GTIN         | <br>4 017918 111397 |
| GTIN         | 4017918111397                                                                                           |

### Technical data

#### Dimensions

|             |          |
|-------------|----------|
| Pitch       | 0.00 mm  |
| Dimension a | 70.98 mm |

#### General

|                                        |                |
|----------------------------------------|----------------|
| Range of articles                      | KGS-PC 4/...-F |
| Number of positions                    | 9              |
| Insulating material group              | I              |
| Insulating material                    | ABS            |
| Flammability rating according to UL 94 | HB             |

#### Standards and Regulations

|                                        |    |
|----------------------------------------|----|
| Flammability rating according to UL 94 | HB |
|----------------------------------------|----|

#### Environmental Product Compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

## Cable housing - KGS-PC 4/ 9-F - 1837382

### Classifications

#### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 27440392 |
| eCl@ss 4.0    | 27260700 |
| eCl@ss 4.1    | 27260700 |
| eCl@ss 5.0    | 27260700 |
| eCl@ss 5.1    | 27261200 |
| eCl@ss 6.0    | 27261200 |
| eCl@ss 7.0    | 27440202 |
| eCl@ss 8.0    | 27440390 |
| eCl@ss 9.0    | 27440392 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 3.0 | EC000058 |
| ETIM 4.0 | EC000437 |
| ETIM 5.0 | EC000437 |
| ETIM 6.0 | EC000437 |
| ETIM 7.0 | EC000437 |

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30211810 |
| UNSPSC 7.0901 | 39121409 |
| UNSPSC 11     | 39121409 |
| UNSPSC 12.01  | 39121409 |
| UNSPSC 13.2   | 31261501 |
| UNSPSC 18.0   | 31261501 |
| UNSPSC 19.0   | 31261501 |
| UNSPSC 20.0   | 31261501 |
| UNSPSC 21.0   | 31261501 |

### Approvals

#### Approvals

---

Approvals

EAC

---

Ex Approvals

---

#### Approval details

## Cable housing - KGS-PC 4/ 9-F - 1837382

### Approvals

EAC




B.01687

### Accessories

#### Accessories

#### Cable housing

Cable housing - KGS-MSTB 2,5/ DST - 1784914

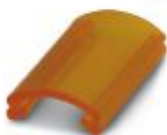

Transparent label carrier, can be marked with marker strips SBS 2.5/7.5

### Mounting material

Bend protection sleeve - CPH 9-15 - 3000768



Bend protection sleeve, for cable diameter of 9 mm ... 15 mm, diameter: 12 mm, color: black

### Terminal marking

Marker for terminal blocks - SBS 2,5/7,5 - 1007604



Marker for terminal blocks, Card, white, unlabeled, can be labeled with: Marker pen, perforated, mounting type: snap into tall marker groove, snap into flat marker groove, for terminal block width: 7.5 mm, lettering field size: 15 x 7.5 mm, Number of individual labels: 10

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[1837382](#)