

Electronic housing - HCS-T MINI C C C C 7035 - 2203130

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Handheld housing, T-Mini, light gray, front level closed, consisting of two half shells with screws

Your advantages

- ✔ Item is from the HCS product range
- ✔ Suitable for handheld devices
- ✔ Ergonomic straight or staggered housing design
- ✔ Integration of LCD displays and membrane keypads
- ✔ Degree of protection: up to IP54
- ✔ Temperature range: -20 °C to +50 °C
- ✔ Shock-resistant ABS plastic
- ✔ Flammability rating UL 94-V0



Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4055626376868

Technical data

Item properties

Type	HCS-T MINI C C C C 7035
Order No.	2203130
Housing type	Handheld housing
Type	stepped
Max. IP code to attain	IP54
Battery compartment	no
Ventilation openings present	no

Measurements

Electronic housing - HCS-T MINI C C C C 7035 - 2203130

Technical data

Measurements

Caption	Schematic representation – for additional information, see product range drawing in the Download Center
Width [w]	85 mm
Height [h]	182.5 mm
Depth [d]	30 mm

Material specifications

Color (RAL)	light gray (7035)
Flammability rating according to UL 94	V0
Housing material	ABS

Ambient conditions

Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 80 °C
Ambient temperature (operation)	-40 °C ... 80 °C

Hammer test

Specification	IEC 60068-2-75:2014-09
Impact energy	0.7 J
Number of drop cycles	5

Thermostability (ball thrust test)

Specification	IEC 60695-10-2:2014-02
Temperature	80 °C
Test duration	1 h
Force	20

Test for assessing the risk of fire (glow wire)

Specification	IEC 60695-2-11:2014-02
Temperature	850 °C
Time of exposure	30 s

Degrees of protection provided by enclosures (IP code)

Specification	IEC 60529:1989-11 + AMD 1:1999-11 + AMD 2:2013-08
Result, degree of protection, IP code	IP40

Packaging information

Pieces per package	1
Denomination packing units	Pcs.


Standards and regulations

Flammability rating according to UL 94	V0
--	----

Drawings

Electronic housing - HCS-T MINI C C C C 7035 - 2203130

Dimensional drawing

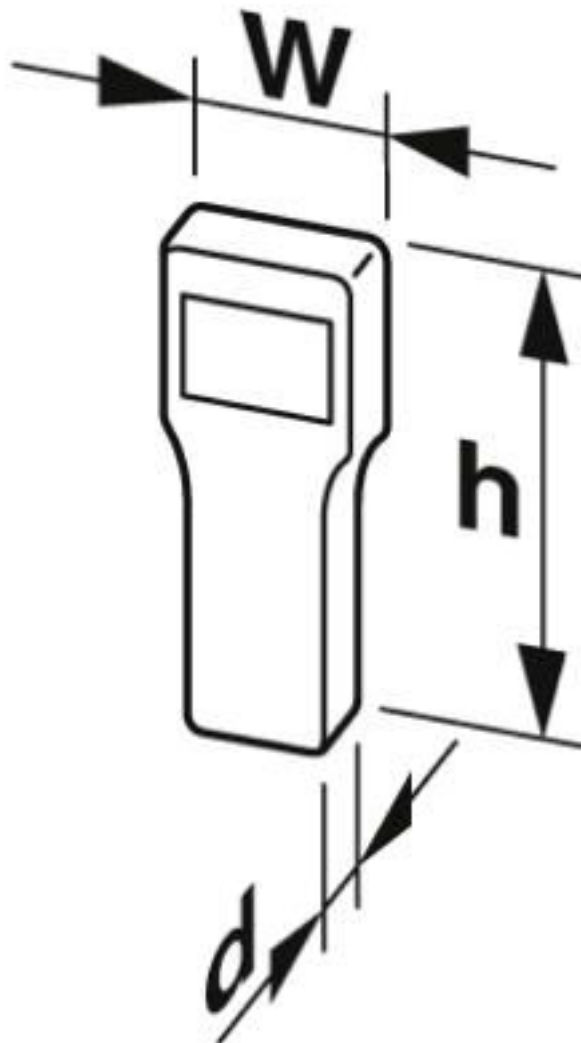

Schematic representation – for additional information, see product range drawing in the Download Center

Classifications

eCl@ss

eCl@ss 10.0.1	27182702
eCl@ss 5.1	27180506
eCl@ss 6.0	27180800
eCl@ss 7.0	27182702
eCl@ss 8.0	27182702
eCl@ss 9.0	27182702

ETIM

ETIM 5.0	EC001031
----------	----------

Electronic housing - HCS-T MINI C C C C 7035 - 2203130

Classifications

ETIM

ETIM 6.0	EC001031
ETIM 7.0	EC001031

Accessories

Accessories

Screwdriver tools

Philips screwdriver - SF-PH 0-60 - 1212558



Screwdriver, PH crosshead, size: PH 0 x 60, 2-component grip, with non-slip grip

Additional products

Seal - HCS-T MINI SEAL - 2203579



Sealing set without battery chamber, including cord and O-rings

Seal - HCS-T MINI D-SEAL 2,8 - 2203738

Sealing frame, self-adhesive, lasered, for 2.8" display



Adhesive - HCS-T MINI W-GLUE - 2203745

Transfer adhesive for display window



Phoenix Contact 2020 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Contact:](#)

[2203130](#)